



Temperature Probes


Housing Style	Part Number	ID Number	Temperature Range	Length (mm)
Pt100 Temperature Probe, 3/4" Tri-Clamp, Ø8 mm	TP-104A-TRI 3/4-H1141-L035	M9910429	-50° to +120°C (-58° to +248°F)	35
	TP-104A-TRI 3/4-H1141-L100	M9910430		100
Pt100 Temperature Probe, Ø3 mm	TP-203A-CF-H1141-L100	M9910402	-30° to +350°C (-22° to +662°F)	100
	TP-203A-CF-H1141-L150	M9910403		150
	TP-203A-CF-H1141-L200	M9910482		200
	TP-203A-CF-H1141-L250	M9910404		250
	TP-203A-CF-H1141-L300	M9910474		300
	TP-203A-CF-H1141-L1000	M9910496		1000
	TP-203A-CF-H1141-L2000	M9910499		2000
Pt100 Temperature Probe, Ø6 mm	TP-206A-CF-H1141-L100	M9910475	-30° to +350°C (-22° to +662°F)	100
	TP-206A-CF-H1141-L150	M9910476		150
	TP-206A-CF-H1141-L200	M9910477		200
	TP-206A-CF-H1141-L300	M9910478		300
	TP-206A-CF-H1141-L500	M9910491		500

Mating cordset for remote connections; RK 4.4T-* -RS 4.4T.

* Length in millimeters.

For technical data see pages C15 - C16.

See Section F for additional cordset information.

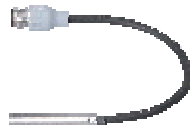

Temperature Probes

Housing Style	Part Number	ID Number	Temperature Range	Length (m)
Pt100 Cable Probe, 4-Pin M12x1 eurofast®, Ø6 mm 	TP-306A-CF-H1141-L1000	M9910479	-50° to +105°C (-58° to +221°F)	1
	TP-306A-CF-H1141-L2000	M9910480		2
	TP-306A-CF-H1141-L5000	M9910481		5

For technical data see page C16.

Rotatable Display

TS400 and TS500 sensors may also be installed horizontally. The display may be electronically inverted 180 degrees by software incorporated within the sensor.



TEMPERATURE