



piconet® stand-alone module for DeviceNet™
4 analogue inputs ±10 V
SDNB-40A-0005

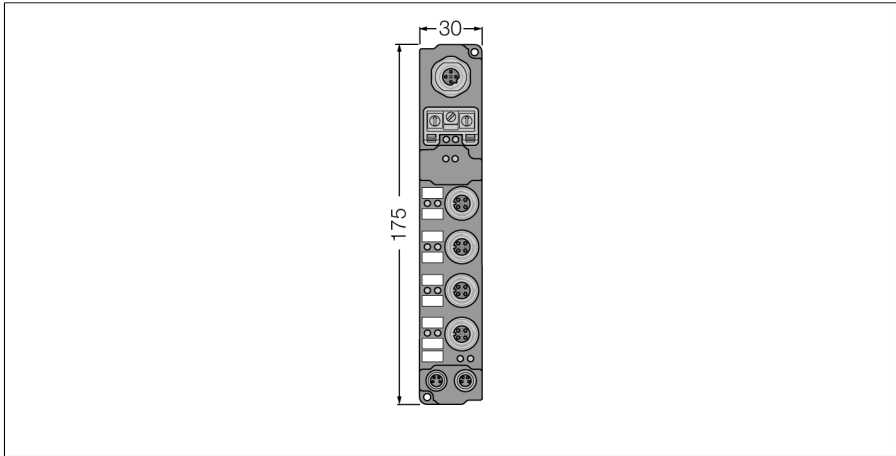


- 4 analogue inputs ±10 V
- Configuration interface
- Parametrizable functions
- Supported via I/O-ASSISTANT 2
- Direct connection to the fieldbus
- Fibre-glass reinforced housing
- Shock and vibration tested
- Encapsulated module electronics
- Metal connector
- Degree of protection IP67


M12 × 1 Fieldbus

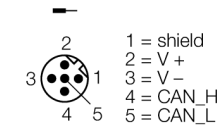


M12 × 1 Input

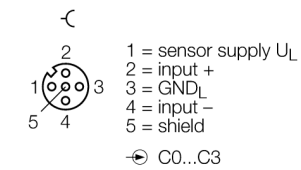

Connection - Inputs

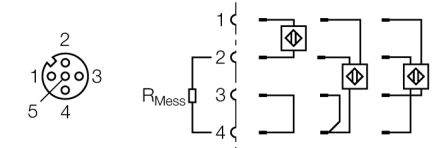

M8 × 1 Power Supply

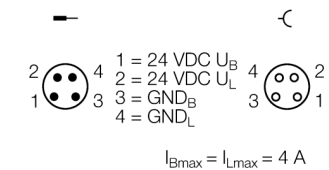

Type designation	SDNB-40A-0005
Ident-No.	6824047
Voltage supply connection	2 x M8
Operating current	≤ 55 mA
Fieldbus transmission rate	125/250/500 kbps
Fieldbus connection technology	1 × M12
Fieldbus addressing	0 to 99
Service interface	parameterisation via I/O-ASSISTANT
Electrical isolation	Fieldbus to operational voltage
Number of channels	4 analogue inputs ± 10 V
Electrical isolation	channels to operational voltage
Vibration test	as per EN 60068-2-6
Shock test	acc. to DIN EN 60068-2-27
Electromagnetic compatibility	according to EN 61000-6-2/EN 61000-6-4
Dimensions (W x L x H)	30 x 175 x 26.5mm
Operating temperature	0...+55 °C
Storage temperature	-25 to 85 °C
Protection class	IP67