


**Switching power supply
IM82-24-2.5**

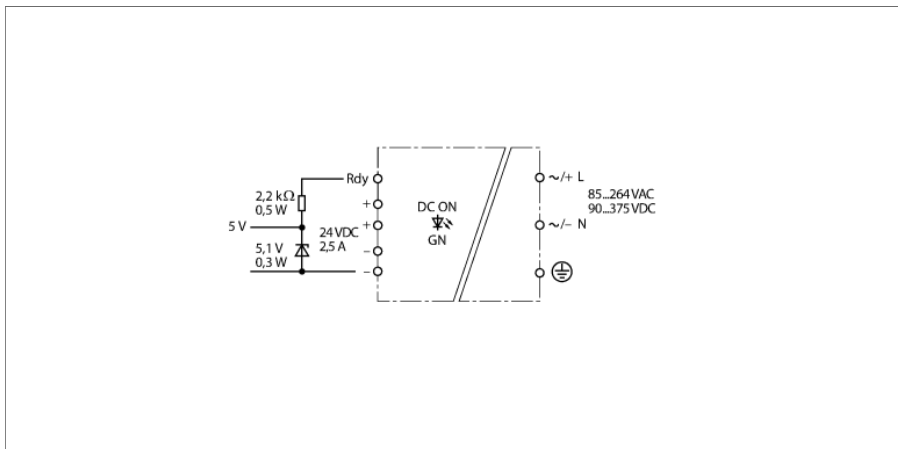


- cULus listed
- Safety extra-low voltage SELV IEC/ EN 60950
- Output voltage adjustable 24...28 VDC
- Nominal current 2.5 A
- Single/parallel operating mode
- Surge protection
- Universal operating voltage
- Mains failure bridging up to 30 ms
- High efficiency
- Natural air cooling


**Switching power supply
IM82-24-2.5**

Type designation	IM82-24-2.5
Ident-No.	7545041
Dimensions (W x L x H)	40.5 x 90 x 114mm
Protection class	IP20


Dimensions

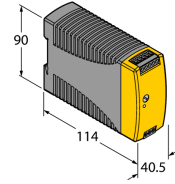

Derating

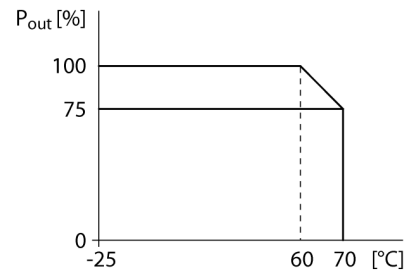

Short-circuit behaviour

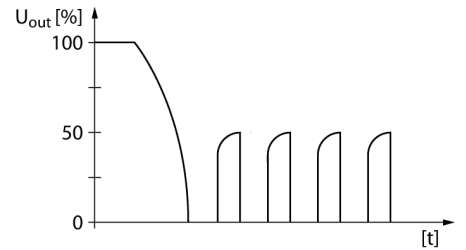

Parallel operation

