


**Switching power supply**  
**IM82-24-5.0**

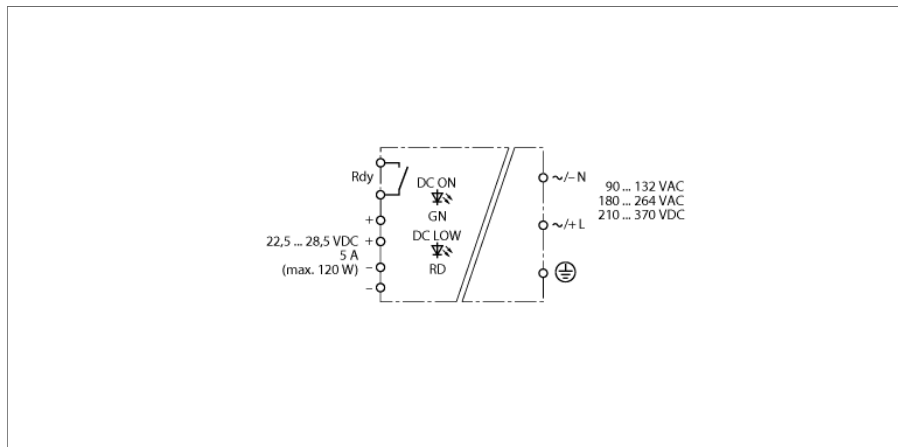


- cULus listed
- Safety extra-low voltage SELV IEC/ EN 60950
- SEMI-F47
- Output voltage adjustable 22.5...28.5 VDC
- Nominal current 5 A
- Single/parallel operating mode
- Surge protection
- Removable terminals
- Universal operating voltage
- Mains failure bridging up to 30 ms
- High efficiency
- Natural air cooling
- Power-good relay


**Switching power supply  
IM82-24-5.0**

|                               |                      |
|-------------------------------|----------------------|
| <b>Type designation</b>       | IM82-24-5.0          |
| Ident-No.                     | 7545042              |
| <b>Dimensions (W x L x H)</b> | 64 x 143.5 x 116.6mm |
| Protection class              | IP20                 |


**Dimensions**

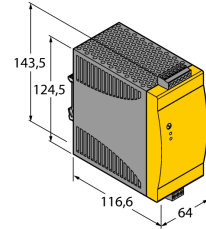

**Derating**

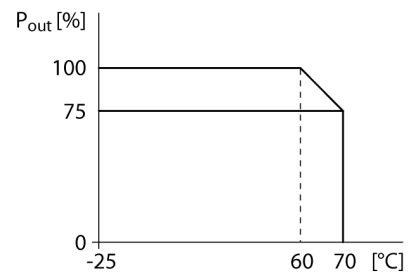

**Short-circuit behaviour**

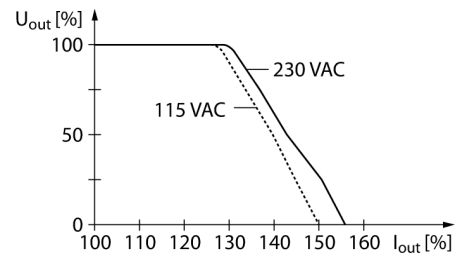

**Parallel operation**

