


# PEP® High Efficiency Permanent Split Capacitor Condenser Fan, 5.6" Diameter, Totally Enclosed, Air Over (TEAO)

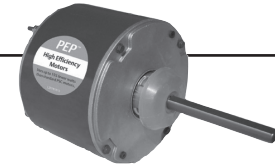


## APPLICATIONS:

High efficiency PSC motors for use on residential and commercial condenser units.

## FEATURES:

- 76% Efficiency Design
- 158°F (70°C) Ambient Design
- Ball Bearings Have All Angle Thrust System
- Class F Insulation
- Designed For Use With 370V Capacitors
- Ball Bearing
- 48" Leads
- Hubless Lead End
- Drain Holes Both Ends
- Reversible Rotation
- Automatic Reset Thermal Overload Protector
- Continuous Duty

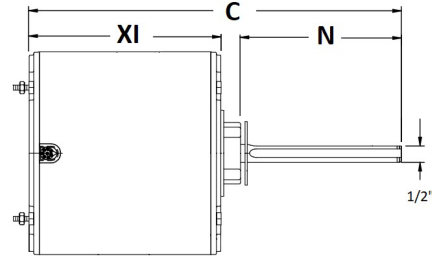

HP	RPM/Spds.	Voltage	Catalog Number	List	Cap. MFD	Amps	Shaft N	Shell XI	Total C	Ship Wt. (lbs)
1/6	1075 RPM	208-230 V	1859PEP	189	5	0.9	4.0	4.6	9.6	10
1/4	1125 RPM	208-230 V	1860PEP	199	5	1.4	4.0	4.5	9.6	12.66
1/4	1115 RPM	460 V	3736PEP	366	7.5	0.7	4.0	4.5	9.6	11.02
1/3	1130 RPM	208-230 V	1861PEP	211	7.5	1.7	3.8	5.0	10.1	15.32
1/3	1115 RPM	460 V	3737PEP	416	7.5	1.0	4.0	5.0	10.1	15.32
1/2	1130 RPM	208-230 V	1862PEP	234	10	2.5	4.0	5.6	10.6	18.02
1/2	1115 RPM	460 V	3738PEP	434	10	1.4	4.0	5.0	10.6	17.78

BRAKEMOTORS

GENERAL PURPOSE  
SINGLE PHASE

HVAC

WASHDOWN

AGRICULTURE

COMMERCIAL PUMP  
MOTORS

CLOSE COUPLED  
PUMP MOTORS

FIRE PUMP  
MOTORS

POOL & SPA  
MOTORS

RESIDENTIAL  
WATER PUMP

ELEVATOR  
GATE & DOOR

