

# Permanent Split Capacitor Flex Mount Direct Drive Fan & Blower 5.0" & 5.6" Diameter, Open Air Over




## APPLICATIONS:

Designed to meet manufacturer's requirements for use on direct drive fan & blowers with flexible ear mounts.

## FEATURES:

- Class B Insulation Unless Noted
- 5.0" Diameter Motors CWLE Rotation
- 5.6" Diameter Motors Reversible Rotation
- Bearings, All Angle Thrust System
- Continuous Duty, Air Over
- 24" Leads
- Automatic Reset Thermal Overload Protector
- PSC Motors Designed For 370V Capacitors
- **Discount Symbol: DS-3HAC**

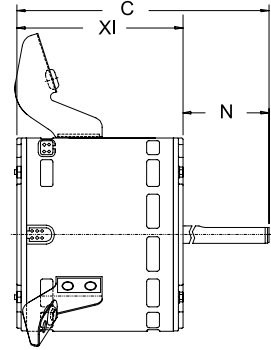

## Permanent Split Capacitor 5.0" Diameter

HP	RPM/ Spd.	Voltage	Catalog Number	Cap MFD	Amps	Shaft N	Shell XI	Total C	Ship Wt.	Notes	OEM
1/5	1050/1	115	2867P	5.0	3.0	3.8	4.5	8.3	8	H16, H22, CI	MI

## Permanent Split Capacitor 5.6" Diameter

HP	RPM/ Spd.	Voltage	Catalog Number	Cap MFD	Amps	Shaft N	Shell XI	Total C	Ship Wt.	Notes	OEM
1/4	1075/3	115	3783	5.0	3.8	5.0	4.3	9.3	15		
	1075/3	208-230	3784	5.0	1.7	5.0	4.3	9.3	11	80	
1/3	825/3	230	8052	15.0	1.9	2.5	4.8	7.3	18	H16	LE
	1000/4	115	9377	5.0	6.0	5.3	4.6	9.8	18	H16	
	1075/3	115	3785	7.5	5.0	5.0	4.6	9.6	15		
1/2	1075/3	208-230	3786	5.0	2.4	5.0	4.3	9.3	15		
	1075/3	115	3787	10.0	7.4	5.0	5.6	10.7	18		
	1075/3	208-230	3788	7.5	3.3	5.0	5.3	10.3	20		

LE = Lennox      MI = Miller

Note CI: Capacitor Included Mounted  
 Note H16: Rotation CCWLE  
 Note H22: Flex Mount is Removable  
 Note 80: Canadian Standard — Connected CCWLE (Reversible)