

## Pool & Spa Motors - Close Coupled Pumps PENTAIR EQ SERIES<sup>®</sup> Replacement Pool Motors



FD4

Open Drip Proof, Premium Efficient, Full Service Factor, Full Rated

### FEATURES:


- Special JMZ Mounting
- 40°C Ambient
- Continuous Duty
- Class F Insulated
- Open Drip Proof
- Permanently Lubricated Ball Bearings
- Rigid Base
- Black Paint
- Special Ground Lug
- 300 Series Stainless Steel Shaft
- **Discount Symbol: DS-FPS**

HP	Phase	RPM	Frame	Voltage	Catalog Number	SF	Full Load		Wgt.
							EFF	PF	
5	1	3600	184JMZ	230	EEQ500	1.15	88.0%	94.0%	78
	3	3600	182JMZ	208-230/460	EEQK500	1.15	89.5%	85.8%	50
7.5	3	3600	184JMZ	208-230/460	EEQK750	1.15	88.5%	87.0%	60
	1	3600	213JMZ	230	EEQ750	1.15	87.0%	92.3%	70
10	3	3600	213JMZ	208-230/460	EEQK1000	1.15	90.2%	79.2%	90
15	3	3600	215JMZ	208-230/460	EEQK1500	1.15	91.0%	82.0%	105

Totally Enclosed Fan Cooled, Premium Efficient, Full Service Factor, Full Rated

### FEATURES:

- Special JMZ Mounting
- 40°C Ambient
- Continuous Duty
- Class F Insulated
- Totally Enclosed Fan Cooled
- Permanently Lubricated Ball Bearings
- Rigid Base
- Black Paint
- Special Ground Lug
- 300 Series Stainless Steel Shaft Extension
- **Discount Symbol: DS-FPS**

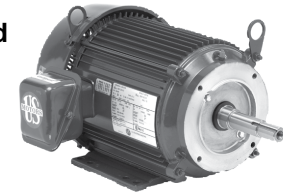

UT4

HP	Phase	RPM	Frame	Voltage	Catalog Number	List	Full Load		Wgt.
							EFF	PF	
5	3	3600	184JMZ	208-230/460	EEQKT500	1.25	88.5%	87.1%	70
7.5	3	3600	213JMZ	208-230/460	EEQKT750	1.25	91.0%	86.8%	105
10	3	3600	215JMZ	208-230/460	EEQKT1000	1.25	91.0%	87.6%	120
15	3	3600	215JMZ	208-230/460	EEQKT1500	1.25	91.0%	85.3%	120