



1/4" System

13/16" System

Fiberglass System

Special Metals


PrimeAngle

Metal Grating

Roofwalk


Index

A1066

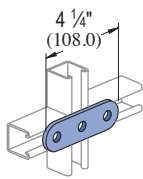


Wt/100 pcs: 26 Lbs (11.8 kg)

A1026

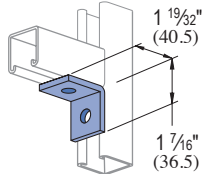


Wt/100 pcs: 17 Lbs (7.7 kg)

A1325

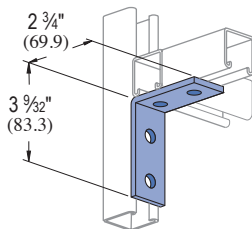

Wt/100 pcs: 38 Lbs (17.2 kg)


A2472 R-L

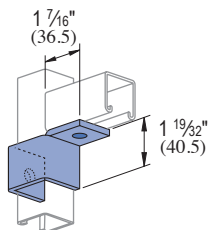

R-As shown
L-Opposite hand


Wt/100 pcs: 33 Lbs (15.0 kg)

A2324

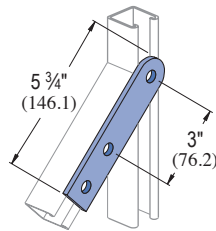


Wt/100 pcs: 39 Lbs (17.7 kg)

A1068

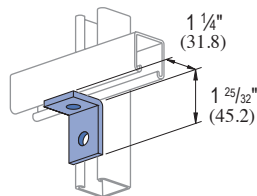


Wt/100 pcs: 17 Lbs (7.7 kg)

A2110

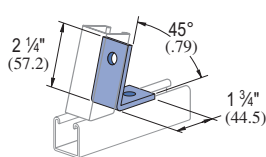


Wt/100 pcs: 23 Lbs (10.4 kg)

A2223

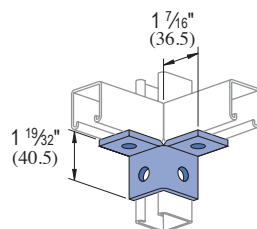


Wt/100 pcs: 34 Lbs (15.4 kg)

A1036

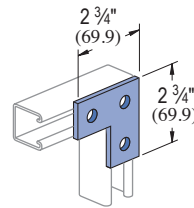


Wt/100 pcs: 27 Lbs (12.2 kg)

A1326

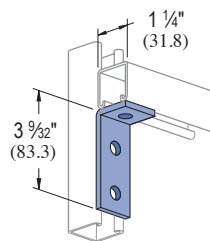


Wt/100 pcs: 27 Lbs (12.2 kg)

A2126

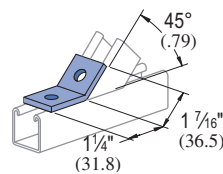


Wt/100 pcs: 17 Lbs (7.7 kg)

A2345

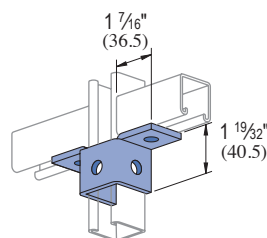


Wt/100 pcs: 41 Lbs (18.6 kg)

A1031

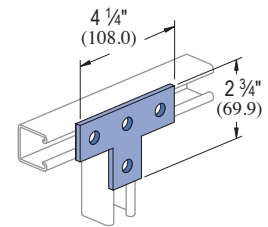


Wt/100 pcs: 34 Lbs (15.4 kg)

A1458

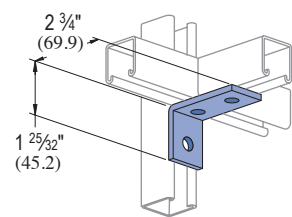


Wt/100 pcs: 27 Lbs (12.2 kg)

A2084

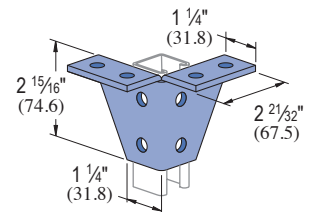

Wt/100 pcs: 90 Lbs (40.8 kg)

A2227

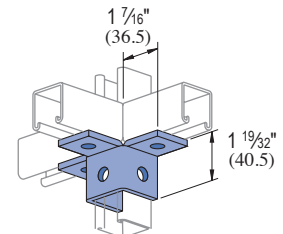

Wt/100 pcs: 52 Lbs (23.6 kg)

Standard Dimensions for 1/4" (31.8 mm) width series channel fittings (Unless Otherwise Shown on Drawing)

Hole Diameter: 13/32" (10.3mm); Hole Spacing - From End: 5/8" (15.9 mm); Hole Spacing - On Center: 1 1/2" (38.1mm); Width: 1 1/4" (31.8mm); Thickness: 3/16" (4.8mm)