



CSW SERIES - PRODUCT SELECTION

Pushbuttons

Types

- F - Flush
- C - Mushroom
- D - Double
- FI - Illuminated Flush
- SI - Illuminated Extended
- CI - Illuminated Mushroom

MULTIPLIER SYMBOL FOR CSW SERIES - Z5

B

Color (see Color Code)

FLUSH

- BF0
- BF1
- BF2
- BF3
- BF4
- BF5



LIST PRICE
\$6.80

MUSHROOM (40mm HEAD)

- BC1
- BC2



LIST PRICE
\$11.00

DOUBLE

BD (IP40)



LIST PRICE
\$15.30

ILLUMINATED FLUSH

- BF10
- BF11
- BF12
- BF13
- BF14



LIST PRICE
\$11.20

ILLUMINATED EXTENDED

- BSI0
- BSI1
- BSI2
- BSI3
- BSI4



LIST PRICE
\$11.00

ILLUMINATED MUSHROOM (40mm HEAD)

- BC10
- BC11
- BC12
- BC13
- BC14



LIST PRICE
\$10.00

Emergency-Stop Pushbuttons

Types

B E

- G - Twist release
- Y - Key release

Pilot Lights

S D

Color (see Color Code)

E-STOP - TWIST RELEASE

● BEG



LIST PRICE
\$16.10

E-STOP - KEY RELEASE

● BEY



LIST PRICE
\$48.00

PILOT LIGHTS

- SD0
- SD1
- SD2
- SD3
- SD4



LIST PRICE
\$9.40

COLOR CODE

Color	Clear/White	Red	Green	Yellow	Blue	Black
Code	0	1	2	3	4	5
Symbol	○	●	●	●	●	●

(1) For increasing the degree of protection to IP66, use the protection cover APBD.

FRACTIONAL HP

GENERAL PURPOSE

NEIMA PREMIUM EFFICIENCY

CRUSHER® DUTY

IEC TRU-METRIC™

PUMP MOTORS

DEFINITE PURPOSE

ADD-ON™ MODIFICATIONS

MOTOR TECHNICAL DATA

DRIVES & SOFT STARTERS

CONTROLS



CSW SERIES - PRODUCT SELECTION

FRACTIONAL HP

GENERAL PURPOSE

NEEMA PREMIUM EFFICIENCY

CRUSHER® DUTY

IEC TRU-METRIC™

PUMP MOTORS

DEFINITE PURPOSE

ADD-ON™ MODIFICATIONS

MOTOR TECHNICAL DATA

DRIVES & SOFT STARTERS

CONTROLS

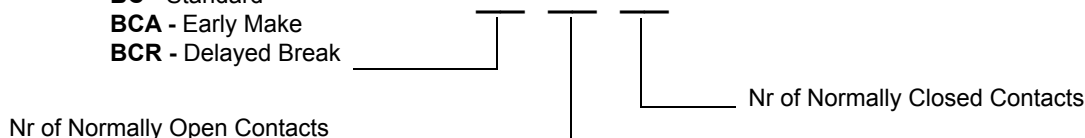
Contact Blocks




Types

BC - Standard

BCA - Early Make

BCR - Delayed Break



SINGLE		DOUBLE	
BC01 - 1NC		BCA10 - 1NOem (early make)	
BC10 - 1NO	LIST PRICE \$5.00	BCR01 - 1NCdb (delayed break)	LIST PRICE \$6.00
		BC11 - 1NO/1NC	
		BC20 - 2NO	LIST PRICE \$9.50

Push-On / Push-Off Block

BR

- Device for flush, extended and mushroom pushbuttons

Note: Use only with single contact blocks.

1NO-contacts must be BCA10 (early make) type.



LIST PRICE
\$9.30

Lamp Blocks

FULL VOLTAGE AC/DC	RESISTOR + DIODE (220 VAC)
BID	BIRD
	
LIST PRICE \$5.10	LIST PRICE \$26.70
- For Ba9s lamps 380V / 2W max.	- Incandescent lamp included (130V, Ba9s)

LED Blocks

BIDL


Type

Voltage level

- 12Vac/Vdc
- 24Vac/Vdc
- 48Vac/Vdc
- 110-130Vac
- 125Vdc
- 220-240Vac

Colors

- 0 White
- 1 Red
- 2 Green
- 3 Yellow
- 4 Blue



LIST PRICE
\$16.00

For 125Vdc only
LIST PRICE
\$18.90

Lamps

INCANDESCENT (BA9S)

L6VI	6V 50-60Hz/DC	LIST PRICE \$9.70
L12VI	12V 50-60Hz/DC	
L24VI	24V 50-60Hz/DC	
L48VI	48V 50-60Hz/DC	
L60VI	60V 50-60Hz/DC	
L130VI	130V 50-60Hz/DC	
L220VI	220V 50-60Hz/DC (Neon)	

