



Sensor/Actuator Module 289 Series

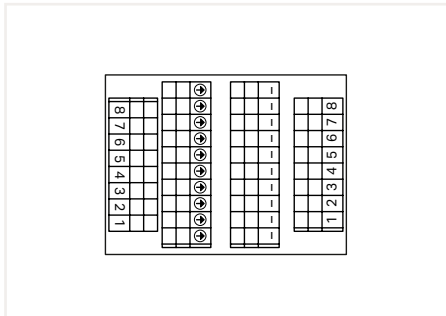

Sensor/Actuator Module; 8-channel digital output;
2 conductors; with functional ground;
with mounting carrier

Item No.	Pack. Unit
289-671	1

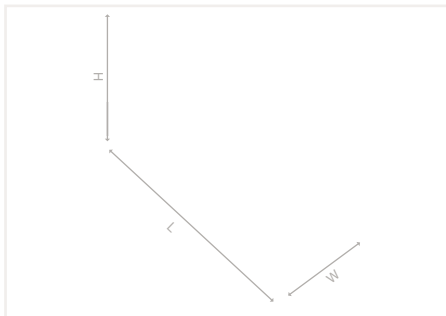

Electrical Data

Operating voltage	≤ 100 VAC; ≤ 125 VDC
Total current	8 A
Current per connection (max.)	1 A

Safety and Protection

Pollution degree	2
Rated voltage	100 V
Rated surge voltage	1.5 kV

Connection Data

Connection technology	CAGE CLAMP®
Solid conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip Length	5 ... 6 mm / 0.2 ... 0.24 inch

Physical Data

Width	56 mm / 2.205 inch
Height from upper-edge of DIN-rail	34 mm / 1.339 inch
Depth	85 mm / 3.346 inch

Mechanical Data

Mounting type	DIN-35 rail
---------------	-------------

Material Data

Weight	70.8 g
--------	--------

Environmental Requirements

Surrounding air temperature (operation)	-20 ... +50 °C
Surrounding air temperature (storage)	-40 ... +70 °C
Relative humidity	≤ 85 % (non-condensing)

6

Accessories



Marking strip; for mounting carrier; 7.5 mm wide;
50 m reel

Item No.	Pack. Unit
709-178	1