


Analog Output; 0 ... 10 VDC



Figure: 750-559



Figure: 753-559

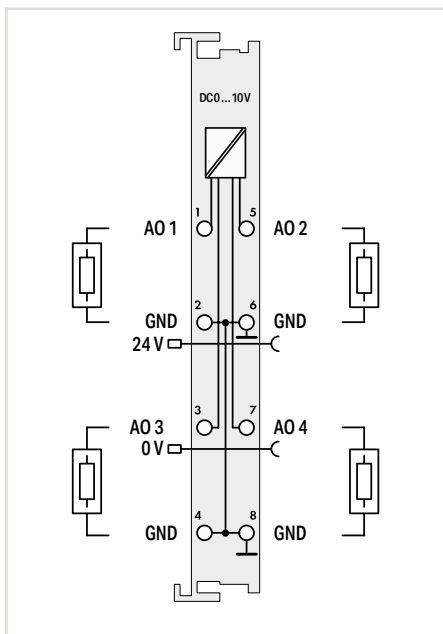

5.5

Item Description	
Version	
Item No.	
Order Text	
Technical Data	
Pluggable connector	
Number of analog outputs	4
Signal type	0 ... 10 V
Actuator connection	2-wire
Load impedance	> 5 kΩ
Resolution	12 bits
Conversion time	10 ms
Output error (max.) at 25 °C	±0.1 % of the upper-range value
Temperature error (max.)	±0.01 % of the upper-range value
Supply voltage (field)	24 VDC (–25 ... +30 %); via power jumper contacts (power supply via blade contact; transmission via spring contact)
Current consumption – system supply (5 V)	125 mA
Data width	4 x 16-bit data; 4 x 8-bit control/status (optional)
Isolation	500 V (system/field)
Surrounding air temperature (operation)	0 ... +55 °C –20 ... +60 °C 0 ... +55 °C
Dimensions W x H x D	12 x 69.8 x 100 mm
Approvals	CE; Marine; OrdLoc/HazLoc; ATEX/IECEX
Accessories	
Pluggable connector	Item No. 753-110
Coding keys	753-150