

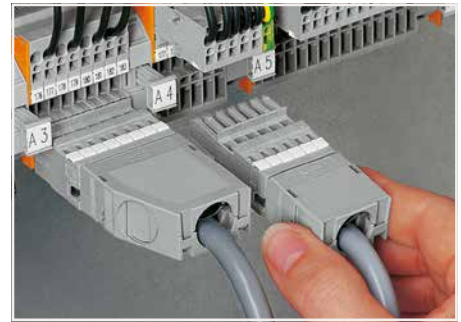
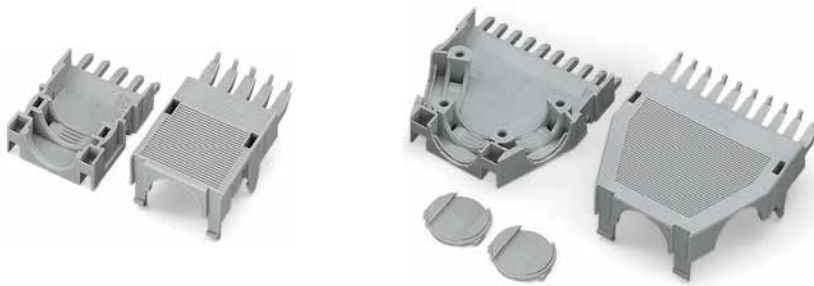


# Strain Relief Housing X-COM®-SYSTEM; for Female Plugs and Male Connectors with CAGE CLAMP® Connection 769 Series

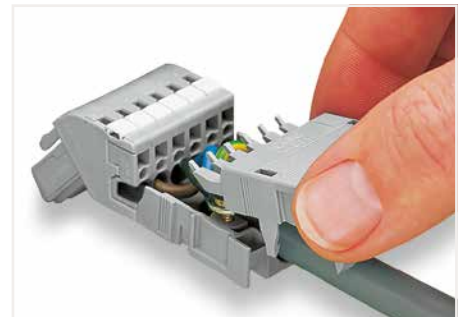

Dimensions (in mm)

Application:  
Strain relief housings for 769 Series

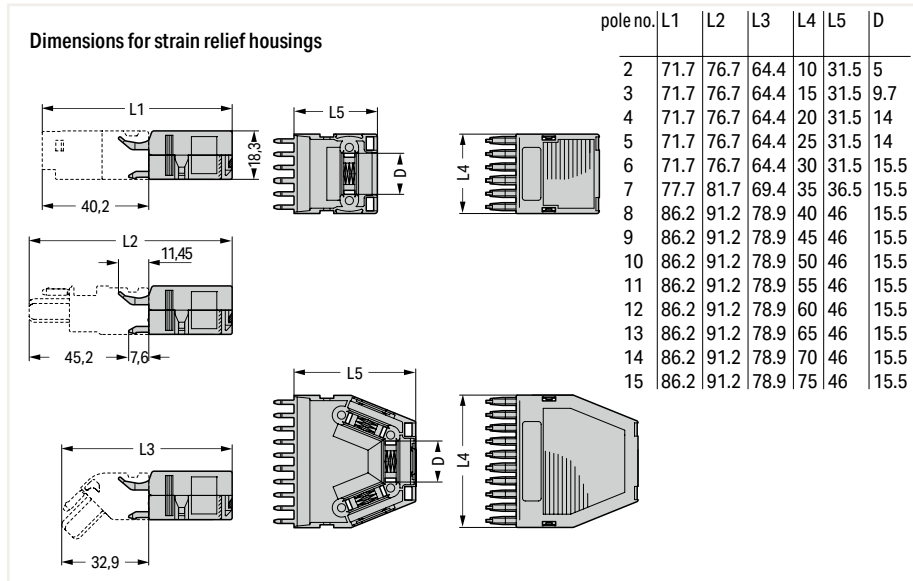

Snapping on a strain relief housing.

Strain relief housing; consists of strain relief support and housing with 1 cable outlet (rear side), 2- to 5-pole only suitable for cable ties (not offered by WAGO); gray

Polzahl	Bestellnr.	VPE
○ 2	769-1602	100
○ 3	769-1603	100
○ 4	769-1604	100
○ 5	769-1605	50

Strain relief housing; consists of strain relief support and housing with 1 cable outlet; gray

Polzahl	Bestellnr.	VPE
○ 6	769-1606	100
○ 7	769-1607	100




Strain relief housing; consists of strain relief support and housing; 6-pole and 1-conductor female plug; angled; 6-pole

Strain relief housing; consists of strain relief support and housing with 2 cable outlets, 1 cover; gray

○ 8	769-1608	50
○ 9	769-1609	50

Strain relief housing; consists of strain relief support and housing with 3 cable outlets, 2 covers; gray

○ 10	769-1610	50
○ 11	769-1611	25
○ 12	769-1612	25
○ 13	769-1613	25
○ 14	769-1614	25
○ 15	769-1615	25

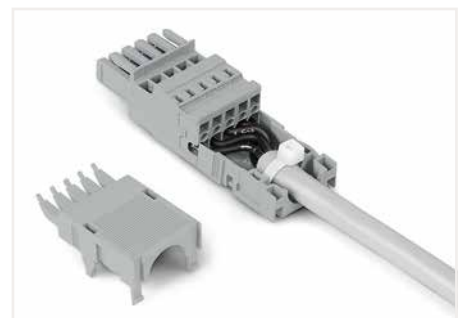

2- to 5-pole strain relief housings feature one cable outlet (rear side).  
6- to 7-pole strain relief housings feature one cable outlet  
8- to 9-pole strain relief housings feature two cable outlets and one cover.  
10- to 16-pole strain relief housings feature three cable outlets and two covers.

**Accessories; item-specific**

WSB Quick Marking System; white; 10 strips with 10 markers/card; for 5 ... 17.5 mm terminal block width

	plain	209-501	5
--	-------	---------	---

**Accessories; item-specific**

Cable clamp; for strain relief












	6 or more poles	209-174	25
--	-----------------	---------	----

**Mounting screw; for cable clamp**

	6 or more poles	209-173	50
--	-----------------	---------	----

## WAGO Female Plug; X-COM®-SYSTEM – 769 Series

### 4 mm<sup>2</sup>

Image	Description	Color	Item No.	PU	Dimensions (W x H x D)	Electrical Data
<b>1-conductor female plug</b>						
	1-conductor female plug; straight; fits into carrier terminal blocks; codable; can be commoned with miniature adjacent jumpers					
	1-pole	○ gray	769-101	200		
	2-pole	○ gray	769-102	100	(5 x pole no.) x 45.2 x 18.3 mm / (0.2 x pole no.) x 1.78 x 0.72 inch	500 V/6 kV/3 ①; I <sub>n</sub> 32 A; 300 V, 20 A ②; 300 V, 20 A ③
	3-pole	○ gray	769-103	50		
	...		...			
15-pole	○ gray	769-115	10			
	1-conductor female plug; angled; fits into carrier terminal blocks; codable					
	1-pole	○ gray	769-101/022-000	200		
	2-pole	○ gray	769-102/022-000	100	(5 x pole no.) x 37.1 x 26.5 mm / (0.2 x pole no.) x 1.46 x 1.04 inch	500 V/6 kV/3 ①; I <sub>n</sub> 32 A; 300 V, 20 A ②; 300 V, 20 A ③
	3-pole	○ gray	769-103/022-000	50		
	...		...			
15-pole	○ gray	769-115/022-000	10			
<b>2-conductor female plug</b>						
	2-conductor female plug; fits into carrier terminal blocks; codable; can be commoned with adjacent and staggered jumpers					
	1-pole	○ gray	769-121	100	(5 x pole no.) x 45.2 x 35.9 mm / (0.2 x pole no.) x 1.78 x 1.41 inch	500 V/6 kV/3 ①; I <sub>n</sub> 32 A; 300 V, 20 A ②; 300 V, 20 A ③
	2-pole	○ gray	769-122	50		
	3-pole	○ gray	769-123	25		
	...		...			
15-pole	○ gray	769-135	5			
<b>Accessories for female plugs</b>						
	Locking lever; for 1-pole female plugs	○ gray	769-428	25		
	Locking lever; for 1-pole female plugs	● orange	769-429	25		
	Locking lever; for female plugs with 2 poles and more	● orange	769-431	25		
	Locking lever; for female plugs with 2 poles and more	○ gray	769-430	25		
	Strain relief plate; 1-pole	○ gray	769-410	25		
	Strain relief plate; 2- ... 3-pole	○ gray	769-411	25		
	Strain relief plate; 4- ... 5-pole	○ gray	769-412	25		
	Strain relief plate; 6- ... 9-pole	○ gray	769-413	25		
	Strain relief plate; 10- ... 15-pole	○ gray	769-414	25		
	Snap-on type strain relief housing; consists of strain relief support and housing; only suitable for cable ties					
	2-pole	○ gray	769-1602	100		
	...		...			
	Snap-on type strain relief housing; consists of strain relief support and housing					
	2-pole	○ gray	769-1606	100		
	...		...			
	15-pole	○ gray	769-1615	25		
	Coding pin; for coding female plugs	● orange	769-435	25		
	Insulation stop; 5 pcs/strip					
	0.08 ... 0.2 mm <sup>2</sup>	○ white	769-470	25		
	0.25 ... 0.5 mm <sup>2</sup>	○ light gray	769-471	25		
	0.75 ... 1 mm <sup>2</sup>	● dark gray	769-472	25		

Conductor range: 0.08 ... 2.5 mm<sup>2</sup>; 28 ... 12 AWG;  
Strip length: 8 ... 9 mm / 0.31 ... 0.35 inch

① 500 V = rated voltage  
6 kV = rated impulse voltage  
3 = pollution degree

Accessories: see page 96.  
Marking: WMB/WMB Inline/Marking strips  
Suitable operating tool: see page 279.