

# EPSITRON®

## Advanced Power Supply System

### New Products



# EPSITRON® ECO POWER

Economical Three-Phase Power Supply



### Universal Supply

- Wide input voltage range: 325 ... 575 VAC
- Efficiently operates on different power grids - no need for additional conversion or adjustment
- High tolerance of voltage fluctuations within a power grid




### Adjustable

- Front-panel adjustable output voltage via potentiometer
- Up to 20% greater output voltage



### Status Monitoring

- Isolated make contact via optocoupler
- Red LED indicates an overload condition
- Green LED indicates DC O.K.
- Ideal for remote monitoring

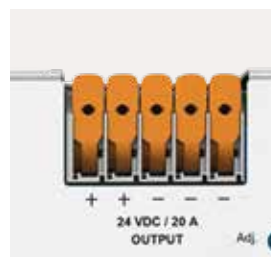


### Fast Wiring

- Comfortable, tool-free wiring with integrated operating levers and Push-in CAGE CLAMP® connection
- Integrated test slots
- Integrated third negative terminal on the output side for direct connection to ground

Three-Phase; Input: 325 ... 575 VAC

24 VDC

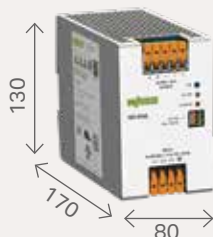

787-2742  
20 A




787-2744  
40 A

# 12 VDC Economical Power Supply



### Universal Supply

- Wide input voltage range: 90 ... 264 VAC
- Efficiently operates on different power grids – no need for additional conversion or adjustment
- High tolerance of voltage fluctuations

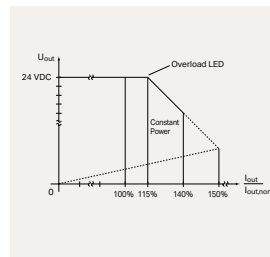

### Robust


- Overload of up to 1.4 times the nominal current with lowered output voltage
- Output shutdown in case of a short circuit
- Automatic restart



DIN rail mount      Chassis mount

### Versatile Mounting Options

- Flexible mounting via DIN rail adapter
- Installation flexibility thanks to chassis-mount clips

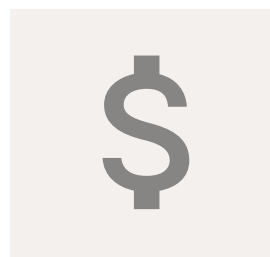

### Highly Economical


- Ease of installation and reliable connections save time and money by increasing up-time
- Budget friendly without sacrificing reliability or field of application

Single-Phase; Input: 90 ... 264 VAC


12 VDC



787-1701  
2 A

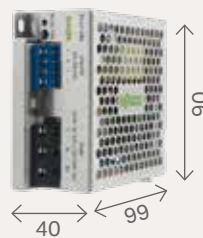

787-1711  
4 A

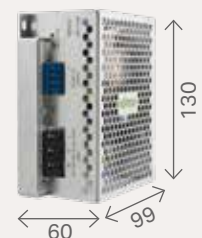

787-1721  
8 A

**WAGO Corporation**  
N120 W19129 Freistadt Road  
Germantown, Wisconsin 53022  
Telephone: 800 / DIN Rail (346-7245)  
Fax: 262 / 255-3232  
info.us@wago.com  
www.wago.us

**Canada**  
WAGO Corporation  
Tel. 800/DIN Rail (346-7245)  
Fax 262/255-3232  
www.wago.ca

**Mexico**  
WAGO Corporation  
Queretaro  
Tel. 001/800/309/5975  
+ 52/442/221/5946  
Fax + 52/442/221/5063  
www.wago.mx

WAGO is a registered trademark of WAGO Verwaltungsgesellschaft mbH.

"Copyright – WAGO Kontakttechnik GmbH & Co. KG – all rights reserved. The content and structure of the WAGO Websites, catalogs, videos, and other WAGO media are subject to copyright. The dissemination or changing of the content of these pages and videos is not permitted. Furthermore, the content may neither be copied nor made available to third parties for commercial purposes. Also subject to copyright are the images and videos that were made available to WAGO Kontakttechnik GmbH & Co. KG by third parties."