

## PCB Terminal Block ▶ 256 Series

CAGE CLAMP® ▶ Actuation type: Push-button ▶ 2.5 mm<sup>2</sup> ▶ Modular terminal block

Pin spacing: 5/5.08 mm / 0.197/0.2 inch

Pin spacing: 7.5/7.62 mm / 0.295/0.3 inch




Pin spacing: 10/10.16 mm / 0.394/0.4 inch



Color	Item No.	PU (SPU)
gray	256-401	600 (100)
blue	256-744	600 (100)
orange	256-746	600 (100)
light gray	256-743	600 (100)
light green	256-747	600 (100)
red	256-740	600 (100)
dark gray	256-742	600 (100)

Color	Item No.	PU (SPU)
gray	256-501	400 (100)
blue	256-754	400 (100)
orange	256-756	400 (100)
light gray	256-753	400 (100)
light green	256-757	400 (100)
red	256-750	400 (100)
dark gray	256-752	400 (100)

Color	Item No.	PU (SPU)
gray	256-601	300 (100)
blue	256-764	300 (100)
orange	256-766	300 (100)
light gray	256-763	300 (100)
light green	256-767	300 (100)
red	256-760	300 (100)
dark gray	256-762	300 (100)

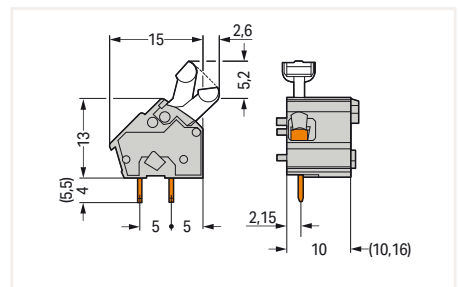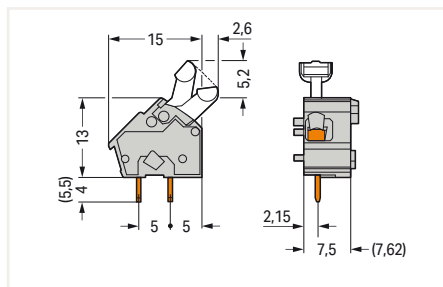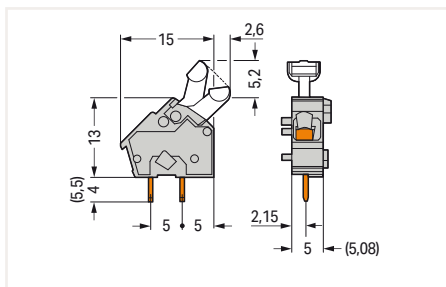

## Accessories; for all products on this page



End plate; 1 mm; snap-on type

Color	Item No.	PU (SPU)
gray	256-100	2000 (100)
blue	256-400	2000 (100)
orange	256-600	2000 (100)
black	256-800	2000 (100)
light gray	256-300	2000 (100)
light green	256-700	2000 (100)
red	256-500	2000 (100)
dark gray	256-200	2000 (100)

PU = Packaging Unit; SPU = Subpackaging Unit; Dimensions in mm

Other variants can be requested via the WAGO sales department or, if necessary, configured at <https://configurator.wago.com/>:

- Other colors
- Versions for Ex e II and Ex i
- Solder pin length: 5.5 mm