

PCB Terminal Block ▶ 236 Series



CAGE CLAMP® ▶ Actuation type: Operating tool ▶ 2.5 mm² ▶ Modular Terminal Block ▶ Pin spacing: 7.5/7.62 mm / 0.295/0.3 inch

Number of solder pins per potential: 1

Number of solder pins per potential: 2



Color	Item No.	PU (SPU)	Color	Item No.	PU (SPU)
gray	236-201	400 (100)	gray	236-501	400 (100)
blue	236-724	400 (100)	blue	236-754	400 (100)
orange	236-726	400 (100)	orange	236-756	400 (100)
black	236-855	400 (100)	black	236-852	400 (100)
light gray	236-723	400 (100)	light gray	236-753	400 (100)
green	236-725	400 (100)	green	236-755	400 (100)
light green	236-727	400 (100)	light green	236-757	400 (100)
brown	236-885	400 (100)	brown	236-882	400 (100)
dark gray	236-722	400 (100)	dark gray	236-752	400 (100)

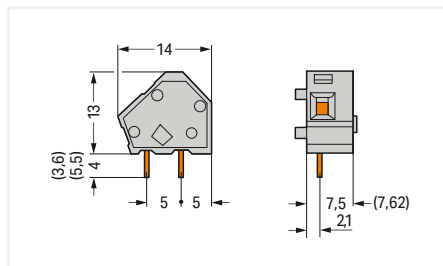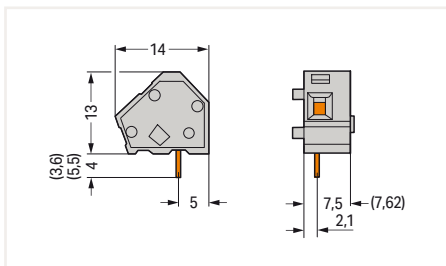

Accessories; for all products on this page



End plate; 1 mm; snap-on type

Color	Item No.	PU (SPU)
gray	236-100	2000 (100)
blue	236-400	2000 (100)
orange	236-600	2000 (100)
black	236-850	2000 (100)
light gray	236-300	2000 (100)
green	236-500	2000 (100)
light green	236-700	2000 (100)
red	236-800	2000 (100)
dark gray	236-200	2000 (100)

PU = Packaging Unit; SPU = Subpackaging Unit; Dimensions in mm

Other variants can be requested via the WAGO sales department or, if necessary, configured at <https://configurator.wago.com/>:

- Versions for Ex e II and Ex i
- Solder pin length: 3.6 mm
- Solder pin length: 5.5 mm