


- 1 500 V = rated voltage
6 kV = rated impulse voltage
3 = pollution degree
(see Section 14)
 - 2 Terminal blocks with a blue insulated housing are suitable for Ex i applications.
- Please observe the application notes:
Insulation stop, page 346
Comb-style jumper bar, page 347
Marking, from page 588
- Approvals and corresponding ratings,
visit www.wago.com


Accessories; 279 Series

Appropriate marking systems:
WMB/WMB Inline/WFB

End and intermediate plate; 2 mm thick

	orange	279-519	200 (25)
	gray	279-518	


Insulation stop; 0.08 ... 0.2 mm² "s" (0.14 mm² "f-st"); 5 pcs/strip

	white	279-470	200 (25)
---	-------	---------	----------


Insulation stop; 0.25 mm²; 5 pcs/strip

	dark gray	279-471	200 (25)
---	-----------	---------	----------


Protective warning marker; with black high-voltage symbol; for 5 terminal blocks

	yellow	279-415	100 (25)
---	--------	---------	----------

Adjacent jumper; insulated; I_N 15 A

	gray	279-402	200 (25)
	yellow-green	279-422	200 (25)


Alternate jumper; insulated; I_N 15 A

	gray	279-409	100 (25)
---	------	---------	----------


Comb-style jumper bar; insulated; I_N = I_N of terminal block

	2-way	279-482	200 (25)
	3-way	279-483	200 (25)

Comb-style jumper bar; insulated; I_N = I_N of terminal block

	10-way	279-490	50 (25)
---	--------	---------	---------


Alternate comb-style jumper bar; insulated; I_N = I_N of terminal block

	2-way	279-492	200 (25)
---	-------	---------	----------


Operating tool; insulated

	2-way	279-432	1
	3-way	279-433	1

Operating tool; insulated

	10-way	279-440	1
---	--------	---------	---


Double-deck marker carrier

	gray	279-529	50 (25)
---	------	---------	---------


Accessories; 279 Series

Appropriate marking systems:
WMB/WMB Inline/Marking Strips

WMB Inline; plain; 2,000 WMB markers (4 mm)/reel; stretchable 4 ... 4.2 mm

	white	2009-114	1
---	-------	----------	---


WMB marking card; white; 10 strips with 10 markers/card; stretchable 4 ... 4.2 mm

	plain	793-4501	5
---	-------	----------	---


WMB marking card; plain; 10 strips with 10 markers/card; stretchable 4 ... 4.2 mm


	yellow	793-4501/000-002	5
	red	793-4501/000-005	5
	blue	793-4501/000-006	5
	gray	793-4501/000-007	5
	orange	793-4501/000-012	5
	light green	793-4501/000-017	5
	green	793-4501/000-023	5
	violet	793-4501/000-024	5

Screwless end stop; for DIN-35 rail; 6 mm wide

	gray	249-116	100 (25)
---	------	---------	----------

Screwless end stop; for DIN-35 rail; 10 mm wide

	gray	249-117	50 (25)
---	------	---------	---------

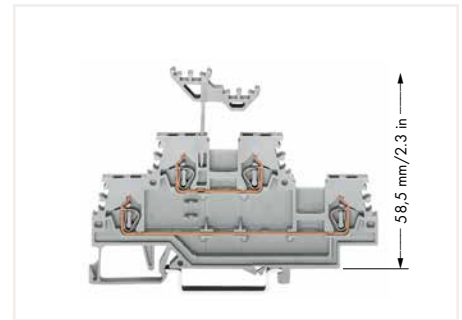

Double-deck marker carrier
(height including marker carrier)