


Double-Deck Terminal Block 2.5 mm²; 280 Series

Technical Data

0.08 ... 2.5 mm ²	28 ... 12 AWG*
500 V/6 kV/3 ①	300 V, 15 A ②
I _N 20 A	300 V, 20 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

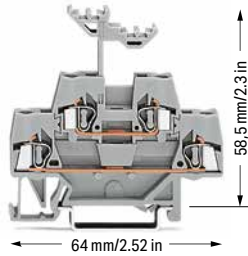

Double-deck terminal block; through/through terminal block

Color	Item No.	Pack. Unit
○ gray	280-519	50
● blue	280-529 ②	50


Other terminal blocks with the same profile:

Diode	280-940/281-410	Page 334
LED	280-943/281-434	Page 334

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-341	100 (25)	
gray	280-340	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-366	100 (25)	

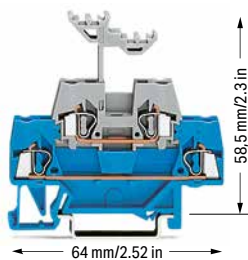

Double-deck terminal block; through/through terminal block

Color	Item No.	Pack. Unit
blue/gray	280-523	50
gray/blue	280-533	50


Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-341	100 (25)	
gray	280-340	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-366	100 (25)	

Technical Data

0.08 ... 2.5 mm ²	28 ... 12 AWG*
500 V/6 kV/3 ①	300 V, 15 A ②
I _N 20 A	300 V, 20 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

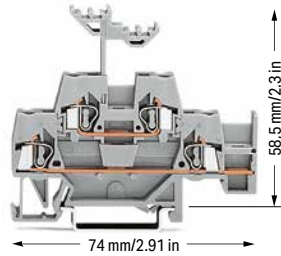


Double-deck terminal block; through/through terminal block; with slot for adjacent jumper

Color	Item No.	Pack. Unit
○ gray	280-520	50
● blue	280-530 ②	50

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-343	100 (25)	
gray	280-342	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-369	100 (25)	

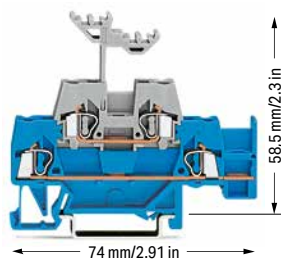

Double-deck terminal block; through/through terminal block; with slot for adjacent jumper

Color	Item No.	Pack. Unit
○ blue/gray	280-524	50
● gray/blue	280-534	50


Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-343	100 (25)	
gray	280-342	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-369	100 (25)	

Technical Data

0.08 ... 2.5 mm ²	28 ... 12 AWG*
500 V/6 kV/3 ①	300 V, 20 A ③
I _N 20 A	300 V, 20 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

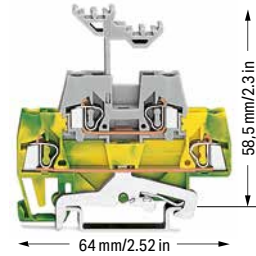


Double-deck terminal block; ground conductor/through terminal block

Color	Item No.	Pack. Unit
green-yellow/gray	280-527	50
green-yellow/blue	280-537	50

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-341	100 (25)	
gray	280-340	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-366	100 (25)	

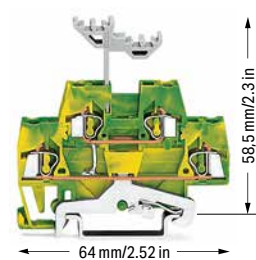

Double-deck terminal block; 4-conductor ground terminal block; internally commoned

Color	Item No.	Pack. Unit
● green-yellow	280-517	50

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-341	100 (25)	
gray	280-340	100 (25)	

Intermediate plate; 1.1 mm thick			
orange	280-366	100 (25)	