




# Quadruple-Deck Rail-Mount Terminal Block for Electric Motor Wiring

## 4 mm<sup>2</sup>; 281 Series

Technical Data	
0.08 ... 4 mm <sup>2</sup>	28 ... 12 AWG
400 V/6 kV/3 ⚡	600 V, 20 A, 50 Hz
I <sub>N</sub> 20 A (2.5 mm <sup>2</sup> )	300 V, 25 A ⚡
I <sub>N</sub> 25 A (4 mm <sup>2</sup> )	
Terminal block width: 6 mm / 0.236 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

Technical Data	
0.08 ... 4 mm <sup>2</sup>	28 ... 12 AWG
400 V/6 kV/3 ⚡	600 V, 20 A, 50 Hz
I <sub>N</sub> 20 A (2.5 mm <sup>2</sup> )	300 V, 25 A ⚡
I <sub>N</sub> 25 A (4 mm <sup>2</sup> )	
Terminal block width: 6 mm / 0.236 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

Technical Data	
0.08 ... 4 mm <sup>2</sup>	28 ... 12 AWG
400 V/6 kV/3 ⚡	600 V, 20 A, 50 Hz
I <sub>N</sub> 20 A (2.5 mm <sup>2</sup> )	300 V, 25 A ⚡
I <sub>N</sub> 25 A (4 mm <sup>2</sup> )	
Terminal block width: 6 mm / 0.236 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

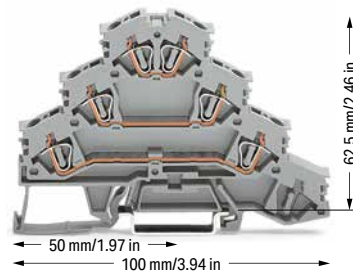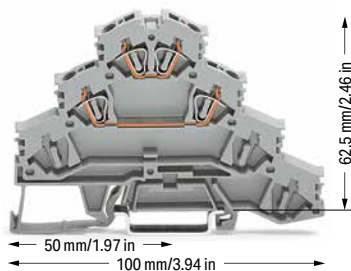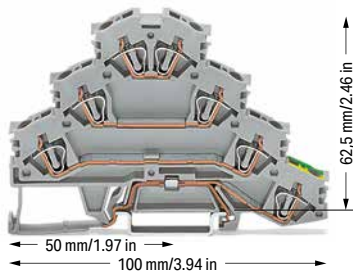

Quadruple-deck rail-mount terminal block; Rail-mount terminal block for electric motor wiring; gray		
	Item No.	Pack. Unit
○ L1 - L2 - L3 - PE	281-530	50

Quadruple-deck rail-mount terminal block; Rail-mount terminal block for electric motor wiring; gray		
	Item No.	Pack. Unit
○ L1 - L2	281-531	50

Quadruple-deck rail-mount terminal block; Rail-mount terminal block for electric motor wiring; gray		
	Item No.	Pack. Unit
○ L1 - L2 - L3	281-532	50

### Accessories; 281 Series

End and intermediate plate; 1 mm thick			
	orange	281-366	100 (25)
	gray	281-365	100 (25)

	white	281-470	200 (25)
--	-------	---------	----------

Insulation stop; 0.25 ... 0.5 mm <sup>2</sup> ; 5 pcs/strip			
	light gray	281-471	200 (25)

Insulation stop; 0.75 ... 1.5 mm <sup>2</sup> ; 5 pcs/strip			
	dark gray	281-472	200 (25)

Comb-style jumper bar; insulated; I <sub>N</sub> = I <sub>N</sub> of terminal block			
	2-way	281-482	100 (25)
	3-way	281-483	100 (25)
	5-way	281-485	100 (25)
	10-way	281-490	50 (25)

Alternate comb-style jumper bar; insulated; I <sub>N</sub> = I <sub>N</sub> of terminal block			
	2-way	281-492	100 (25)

Operating tool; insulated			
	2-way	280-432	1
	3-way	280-433	1
	5-way	281-440	1

Test plug; with 500 mm cable; 2 mm Ø; max. 42 V			
	red	210-137	50

Test plug; with 500 mm cable; 2.3 mm Ø; max. 42 V			
	yellow	210-137	50

### Appropriate marking systems: WMB/Marking strips

Marking strip; plain; 7.5 mm wide; 50 m reel			
	translucent	709-177	1

WMB marking card; white; 10 strips with 10 markers/card; stretchable 5 ... 5.2 mm			
	plain	793-5501	5

WMB marking card; plain; 10 strips with 10 markers/card; stretchable 5 ... 5.2 mm			
	yellow	793-5501/000-002	5
	red	793-5501/000-005	5
	blue	793-5501/000-006	5
	gray	793-5501/000-007	5
	orange	793-5501/000-012	5
	light green	793-5501/000-017	5
	green	793-5501/000-023	5
	violet	793-5501/000-024	5

Screwless end stop; for DIN-35 rail; 6 mm wide			
	gray	249-116	100 (25)

Screwless end stop; for DIN-35 rail; 10 mm wide			
	gray	249-117	50 (25)