


Disconnect/Test Terminal Block; with Disconnect Tab 2.5 mm²; 280 Series

Technical Data	
0.08 ... 2.5 mm ²	28 ... 12 AWG*
400 V/6 kV/3 ①	300 V, 15 A ②
I _N 10 A	300 V, 15 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

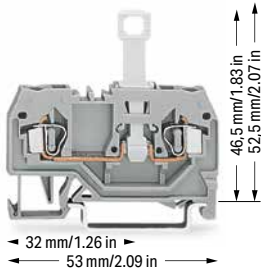

2-conductor disconnect terminal block; with disconnect tab

Color	Item No.	Pack. Unit
○ gray	280-912	50
● blue	280-914	50
● orange	280-913	50


Other terminal blocks with the same profile:		
Through	280-901	Page 236

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-309	100 (25)	
gray	280-308	100 (25)	
light gray	280-356	100 (25)	

Separator; oversized; 2 mm thick			
orange	280-311	100 (25)	
gray	280-310	100 (25)	
light gray	280-357	100 (25)	

Technical Data	
0.08 ... 2.5 mm ²	28 ... 12 AWG*
400 V/6 kV/3 ①	300 V, 15 A ②
I _N 10 A	600 V, 15 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

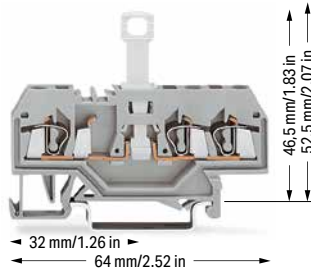

3-conductor disconnect terminal block; with disconnect tab

Color	Item No.	Pack. Unit
○ gray	280-683	50


Other terminal blocks with the same profile:		
Through	280-681	Page 236

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-326	100 (25)	
gray	280-324	100 (25)	
light gray	280-358	100 (25)	

Separator; oversized; 2 mm thick			
orange	280-346	100 (25)	
gray	280-344	100 (25)	
light gray	280-359	100 (25)	

Technical Data	
0.08 ... 2.5 mm ²	28 ... 12 AWG*
400 V/6 kV/3 ①	300 V, 15 A ②
I _N 10 A	600 V, 15 A ③
Terminal block width: 5 mm / 0.197 inch	
8 ... 9 mm / 0.31 ... 0.35 inch	

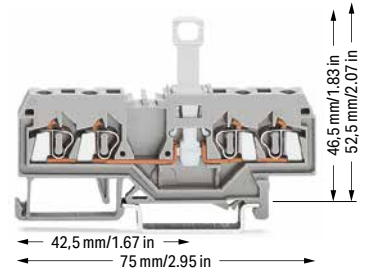

4-conductor disconnect terminal block; with disconnect tab


Color	Item No.	Pack. Unit
○ gray	280-836	50
● blue	280-839	50
● orange	280-805	50

Other terminal blocks with the same profile:		
Through	280-833	Page 236

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-315	100 (25)	
gray	280-314	100 (25)	
light gray	280-352	100 (25)	

Separator; oversized; 2 mm thick			
orange	280-335	100 (25)	
gray	280-334	100 (25)	
light gray	280-353	100 (25)	

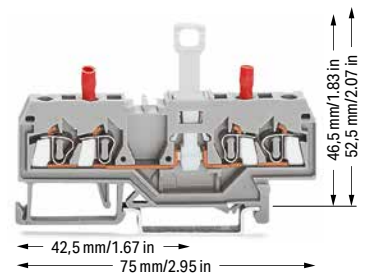

2-conductor disconnect/test terminal block; with disconnect tab; with integrated test sockets

Color	Item No.	Pack. Unit
○ gray	280-829	50

Accessories; item-specific

End and intermediate plate; 2.5 mm thick			
orange	280-315	100 (25)	
gray	280-314	100 (25)	
light gray	280-352	100 (25)	

Separator; oversized; 2 mm thick			
orange	280-335	100 (25)	
gray	280-334	100 (25)	
light gray	280-353	100 (25)	