


2-Pin/2-Pin Double-Deck Carrier Terminal Block X-COM®-SYSTEM 870 Series


Technical Data	
500 V/6 kV/3 ①	
I _N 16 A	
Terminal block width: 5 mm / 0.197 inch	

Technical Data	
Terminal block width: 5 mm / 0.197 inch	

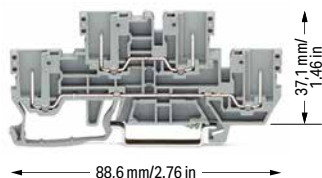


2-pin/2-pin double-deck carrier terminal block; Through/through terminal block; Gray housing

	Item No.	Pack. Unit
○ L/L	870-151	50

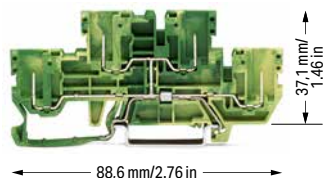

4-pin double-deck carrier block; 4-pin ground conductor block; internally commoned; Green-yellow housing

	Item No.	Pack. Unit
● PE	870-157	50

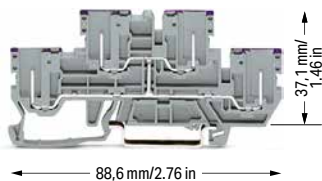

4-pin double-deck carrier terminal block; 4-pin through terminal block; internally commoned; Violet conductor entry; Gray housing

	Item No.	Pack. Unit
○ L	870-158	50

- ① 500 V = rated voltage
6 kV = rated impulse voltage
3 = pollution degree
(see Section 14)

Note: 2-conductor female plugs cannot be used.

Approvals and corresponding ratings, visit www.wago.com

Accessories; 870 Series

Appropriate marking systems:
Mini-WSB/Mini-WSB Inline/WMB/WMB Inline

End and intermediate plate; 1 mm thick			
	orange	870-169	100 (25)
	gray	870-168	100 (25)

Coding pin; for coding female plugs			
	orange	769-435	100 (25)

Push-in type jumper bar; insulated; I _N 18 A; light gray			
	2-way	870-402	200 (25)
	3-way	870-403	200 (25)
	4-way	870-404	100 (25)
	5-way	870-405	100 (25)
	6-way	870-406	100 (25)
	7-way	870-407	100 (25)
	8-way	870-408	100 (25)
	9-way	870-409	100 (25)
	10-way	870-410	50 (25)

Push-in type jumper bar; insulated; I _N 18 A; light gray			
	1 to 3	870-433	200 (25)
	1 to 4	870-434	200 (25)
	1 to 5	870-435	100 (25)
	1 to 6	870-436	100 (25)
	1 to 7	870-437	100 (25)
	1 to 8	870-438	100 (25)
	1 to 9	870-439	100 (25)
	1 to 10	870-440	50 (25)

Pin cover; with Mini-WSB marker slot			
	gray	769-438	100 (25)
	orange	769-439	100 (25)

1-connector female plug; straight			
	gray	769-101	200

1-conductor female plug; angled			
	gray	769-101/022-000	200

Mini-WSB marking card; white; 10 strips with 10 markers/ card; 5 mm wide markers			
	plain	248-501	5

Mini-WSB marking card; plain; 10 strips with 10 markers/ card; 5 mm wide markers			
	yellow	248-501/000-002	5
	red	248-501/000-005	5
	blue	248-501/000-006	5
	gray	248-501/000-007	5
	orange	248-501/000-012	5
	light green	248-501/000-017	5
	green	248-501/000-023	5
	violet	248-501/000-024	5

6