

## 2-Conductor/2-Pin Double-Deck Carrier Terminal Block X-COM®-SYSTEM 2.5 (4 "f-st") mm<sup>2</sup>; 870 Series

### Technical Data


0.08 ... 2.5 (4 "f-st") mm<sup>2</sup> ① | 28 ... 12 AWG

500 V/6 kV/3 ②

I<sub>N</sub> 16 A

Terminal block width: 5 mm / 0.197 inch

6 ... 7 mm / 0.24 ... 0.28 inch

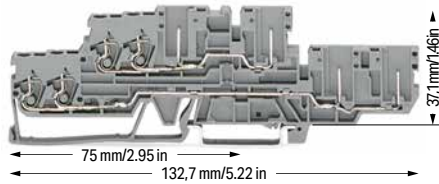

2-conductor/2-pin double-deck carrier terminal block; Through/through terminal block; Gray housing


	Item No.	Pack. Unit
○ L/L	870-131	40

### Technical Data

0.08 ... 2.5 (4 "f-st") mm<sup>2</sup> ① | 28 ... 12 AWG

Terminal block width: 5 mm / 0.197 inch

6 ... 7 mm / 0.24 ... 0.28 inch

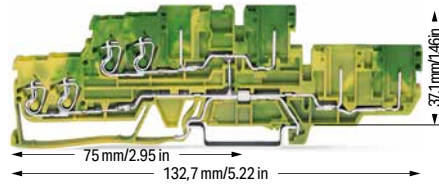

4-conductor/4-pin double-deck carrier block; 4-conductor/4-pin ground conductor block; internally commoned; Green-yellow housing

	Item No.	Pack. Unit
● PE	870-137	40

① Max. insulation diameter: 4.4 mm

② 500 V = rated voltage  
6 kV = rated impulse voltage  
3 = pollution degree  
(see Section 14)

Note: 2- and 1-conductor angled female plugs cannot be used.

Please observe the application notes:  
Insulation stop, page 346  
Marking, from page 589

Approvals and corresponding ratings, visit [www.wago.com](http://www.wago.com)

### Accessories; 870 Series

Appropriate marking systems:  
Mini-WSB/Mini-WSB Inline/WMB/WMB Inline

#### End and intermediate plate; 1 mm thick

orange	870-149	100 (25)
gray	870-148	100 (25)

#### Insulation stop; 0.08 ... 0.2 mm<sup>2</sup> "s" (0.14 mm<sup>2</sup> "f-st"); 5 pcs/strip

white	280-470	200 (25)
-------	---------	----------

#### Insulation stop; 0.25 ... 0.5 mm<sup>2</sup>; 5 pcs/strip

light gray	280-471	200 (25)
------------	---------	----------

#### Insulation stop; 0.75 ... 1 mm<sup>2</sup>; 5 pcs/strip

dark gray	280-472	200 (25)
-----------	---------	----------

#### Coding pin; for coding female plugs

orange	769-435	100 (25)
--------	---------	----------

#### Push-in type jumper bar; insulated; I<sub>N</sub> 18 A; light gray

2-way	870-402	200 (25)
3-way	870-403	200 (25)
4-way	870-404	100 (25)
5-way	870-405	100 (25)
6-way	870-406	100 (25)
7-way	870-407	100 (25)
8-way	870-408	100 (25)
9-way	870-409	100 (25)
10-way	870-410	50 (25)

#### Push-in type jumper bar; insulated; I<sub>N</sub> 18 A; light gray


1 to 3	870-433	200 (25)
1 to 4	870-434	200 (25)
1 to 5	870-435	100 (25)
1 to 6	870-436	100 (25)
1 to 7	870-437	100 (25)
1 to 8	870-438	100 (25)
1 to 9	870-439	100 (25)
1 to 10	870-440	50 (25)

#### Pin cover; with Mini-WSB marker slot

gray	769-438	100 (25)
orange	769-439	100 (25)

#### 1-connector female plug; straight

gray	769-101	200
------	---------	-----

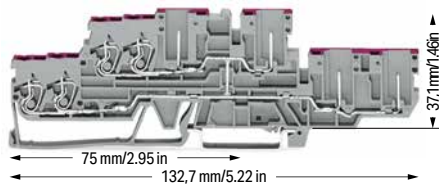

4-conductor/4-pin double-deck carrier terminal block; 4-conductor/4-pin through terminal block; internally commoned; Violet conductor entry; Gray housing

	Item No.	Pack. Unit
○ L	870-138	40