
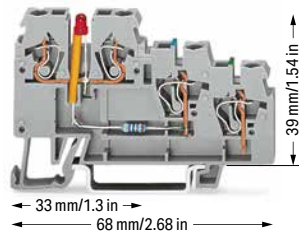


# 3-Conductor Actuator Terminal Block and 3-Conductor Actuator LED Terminal Block 2.5 mm<sup>2</sup>; 270 Series

Technical Data	
0.08 ... 2.5 mm <sup>2</sup>	28 ... 12 AWG*
250 V/4 kV/3 ①	300 V, 20 A ②
I <sub>N</sub> 18 A ②	300 V, 10 A ③
Terminal block width: 5 mm / 0.197 inch	
6 ... 7 mm / 0.24 ... 0.28 inch	



Technical Data	
0.08 ... 2.5 mm <sup>2</sup>	28 ... 12 AWG*
24 VDC ③	
Terminal block width: 5 mm / 0.197 inch	
6 ... 7 mm / 0.24 ... 0.28 inch	

- \*12 AWG: THHN, THWN
- ① 250 V = rated voltage  
4 kV = rated impulse voltage  
3 = pollution degree (see Section 14)
- ② Other voltages are available upon request.  
LED power consumption: 4.8 mA
- See application notes for:  
Insulation stop, page 331  
Marking, from page 589
- Approvals and corresponding ratings,  
visit [www.wago.com](http://www.wago.com)

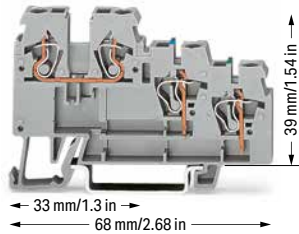

270-572

270-585

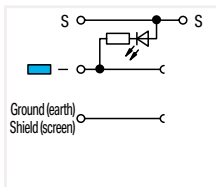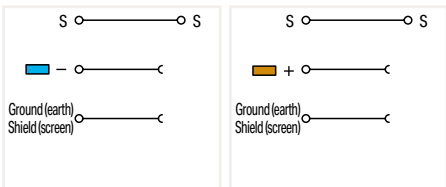

3-conductor actuator terminal block		
Color	Item No.	Pack. Unit
○ gray	270-572	50

3-conductor actuator LED terminal block; for PNP (high-side) switching actuators; Red LED		
Color	Item No.	Pack. Unit
○ gray	270-572/281-434	50

3-conductor actuator terminal block		
Color	Item No.	Pack. Unit
○ gray	270-585	50

**Accessories; 870 Series**  
Appropriate marking systems:  
Mini-WSB/Mini-WSB Inline/WMB/WMB Inline

End and intermediate plate; 1 mm thick; for triple-deck terminal blocks

orange	270-321	100 (25)
gray	270-319	100 (25)

Insulation stop; 0.08 ... 0.2 mm<sup>2</sup> "s" (0.14 mm<sup>2</sup> "f-st"); 5 pcs/strip

white	280-470	200 (25)
-------	---------	----------

Insulation stop; 0.25 ... 0.5 mm<sup>2</sup>; 5 pcs/strip

light gray	280-471	200 (25)
------------	---------	----------

Insulation stop; 0.75 ... 1 mm<sup>2</sup>; 5 pcs/strip

dark gray	280-472	200 (25)
-----------	---------	----------

Push-in type jumper bar; uninsulated; I<sub>N</sub> 18 A  
Jumpers can be shortened using an electronic side cutter.

9-way	270-409	200 (25)
17-way	270-417	200 (25)
80-way	270-480	100 (25)

Push-in type jumper bar; insulated; I<sub>N</sub> 18 A; light gray

2-way	870-402	200 (25)
3-way	870-403	200 (25)
4-way	870-404	100 (25)
5-way	870-405	100 (25)
6-way	870-406	100 (25)
7-way	870-407	100 (25)
8-way	870-408	100 (25)
9-way	870-409	50 (25)

Mini-WSB marking card; white; 10 strips with 10 markers/card; 5 mm wide markers


plain	248-501	5
-------	---------	---

WMB marking card; white; 10 strips with 10 markers/card; stretchable 5 ... 5.2 mm

plain	793-5501	5
-------	----------	---



Operating tool with a partially insulated shaft; Type 2; (3.5 x 0.5) mm blade

	210-720	1
--	---------	---

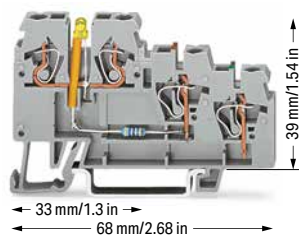

270-577

270-586

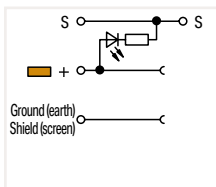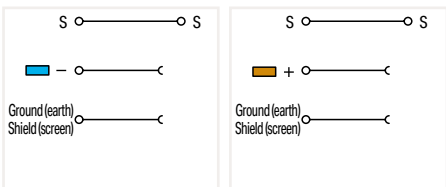

3-conductor actuator supply terminal block		
Color	Item No.	Pack. Unit
○ orange	270-577	10

3-conductor actuator LED terminal block; for NPN (low-side) switching actuators; Yellow LED		
Color	Item No.	Pack. Unit
○ gray	270-585/281-507	50

3-conductor actuator supply terminal block		
Color	Item No.	Pack. Unit
○ orange	270-586	10