




Disconnect/Test Terminal Block

6 mm²; 282 Series

Technical Data	
0.2 ... 6 mm ²	24 ... 10 AWG
400 V/6 kV/3 ①	300 V, 30 A ②
I _N 41 A	300 V, 40 A ③
Terminal block width: 8 mm / 0.315 inch	
12 ... 13 mm / 0.47 ... 0.51 inch	

Technical Data	
0.2 ... 6 mm ²	24 ... 10 AWG
400 V/6 kV/3 ①	300 V, 30 A ②
I _N 41 A	300 V, 40 A ③
Terminal block width: 8 mm / 0.315 inch	
12 ... 13 mm / 0.47 ... 0.51 inch	


Technical Data	
0.2 ... 6 mm ²	24 ... 10 AWG
400 V/6 kV/3 ①	300 V, 30 A ②
I _N 41 A	300 V, 40 A ③
Terminal block width: 8 mm / 0.315 inch	
12 ... 13 mm / 0.47 ... 0.51 inch	

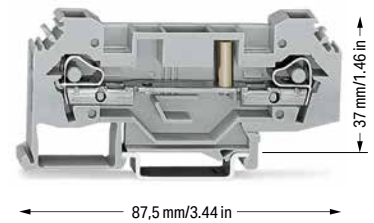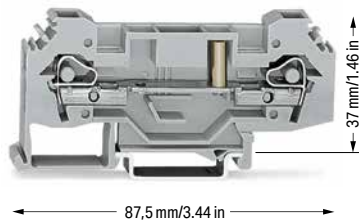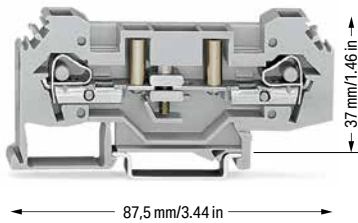



Disconnect/test terminal block; with 4 mm Ø test sockets		
Color	Item No.	Pack. Unit
○ gray	282-131	25


Through terminal block		
Color	Item No.	Pack. Unit
○ gray	282-133	25


Disconnect/test terminal block; without test sockets		
Color	Item No.	Pack. Unit
○ gray	282-135	25

Accessories; item-specific			
Alternate jumper; insulated; I _N 41 A			
	gray	282-409	100 (25)

Accessories; item-specific			
Alternate jumper; insulated; I _N 41 A			
	gray	282-409	100 (25)


 
Accessories; item-specific			
Alternate jumper; insulated; I _N 41 A			
	gray	282-409	100 (25)


Accessories; item-specific			
Lock-out; prevents reclosing of slide link; snap-on type			
	orange	282-137	100 (25)


Accessories; item-specific			
Lock-out; prevents reclosing of slide link; snap-on type			
	orange	282-137	100 (25)


Accessories; 282 Series


Appropriate marking system: WMB


End and intermediate plate; 4 mm thick			
	gray	282-315	50 (25)
	orange	282-314	50 (25)


Screwless end stop; for DIN-35 rail; 6 mm wide			
	gray	249-116	100 (25)


Protective warning marker; with black high-voltage symbol; for 5 terminal blocks			
	yellow	282-405	100 (25)

Screwless end stop; for DIN-35 rail; 10 mm wide			
	gray	249-117	50 (25)

Adjacent jumper; insulated; I _N 41 A			
	gray	282-402	100 (25)

Test plug adapter; 8.3 mm wide; for 4 mm Ø test plug; for 1.5 ... 10 mm ² terminal blocks			
	gray	209-170	50 (25)

B-type test plug module; snaps together; 8 mm wide			
	gray	709-310	100 (25)

B-type spacer module; snaps together; 8 mm wide			
	gray	709-311	100 (25)

10