

# Modular PCB Terminal Block; with Push-Buttons; 2 Solder Pins/Pole; 1.5 mm<sup>2</sup>; Pin Spacing: 5/5.08 mm, 7.5/7.62 mm, 10/10.16 mm 235 Series

Pin spacing: 5/5.08 mm / 0.2 inch

Pin spacing: 7.5/7.62 mm / 0.3 inch


Pin spacing: 10/10.16 mm / 0.4 inch



2


Color	Item No.	Pack. Unit
○ gray	235-401/331-000	800 (100)
● red	235-740/331-000	800 (100)
● yellow	235-741/331-000	800 (100)
● dark gray	235-742/331-000	800 (100)
○ light gray	235-743/331-000	800 (100)
● blue	235-744/331-000	800 (100)
○ white	235-745/331-000	800 (100)
● orange	235-746/331-000	800 (100)
● light green	235-747/331-000	800 (100)
● black	235-748/331-000	800 (100)
● violet	235-749/331-000	800 (100)

Dimensions (in mm):

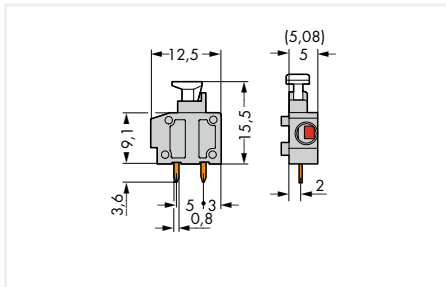


Color	Item No.	Pack. Unit
○ gray	235-501/331-000	600 (100)
● dark gray	235-752/331-000	600 (100)
○ light gray	235-753/331-000	600 (100)
● blue*	235-754/331-000	600 (100)
● orange	235-756/331-000	600 (100)
● light green	235-757/331-000	600 (100)
● black	235-758/331-000	600 (100)

Dimensions (in mm):

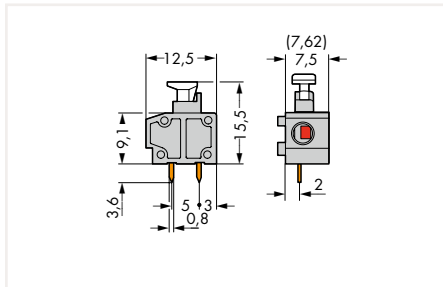

Color	Item No.	Pack. Unit
○ gray	235-801/331-000	400 (100)
● dark gray	235-762/331-000	400 (100)
○ light gray	235-763/331-000	400 (100)
● blue*	235-764/331-000	400 (100)
● orange	235-766/331-000	400 (100)
● light green	235-767/331-000	400 (100)
● black	235-768/331-000	400 (100)

Dimensions (in mm):

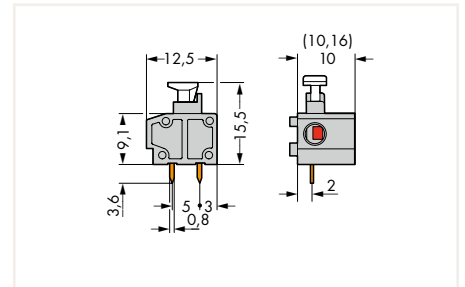

\*Suitable for Ex i applications

Accessories, for all products on this page



Spacer, doubles 5/5.08 mm (0.2 inch) pin spacing

Color	Item No.	Pack. Unit
○ gray	235-701	100

End plates for modular terminal blocks;  
snap-on type; 1 mm thick

Color	Item No.	Pack. Unit
○ gray	235-100	100
● dark gray	235-200	100
○ light gray	235-300	100
● blue	235-400	100
● black	235-500	100
● yellow	235-550	100
● orange	235-600	100
● violet	235-650	100
● light green	235-700	100
● red	235-800	100
○ white	235-850	100

Available upon request (depending on quantity required):

- Other colors