

1-Conductor/1-Pin, 2-Conductor/1-Pin and 2-Conductor/2-Pin Carrier Terminal Block




X-COM®S-SYSTEM-MINI

1 (1.5) mm²; 2020 Series

Technical Data	
0.14 ... 1 (1.5) mm ² ①	24 ... 16 AWG
500 V/6 kV/3 ②	300 V, 10 A ③
I _N 13.5 A ③	300 V, 10 A ④
Terminal block width: 3.5 mm / 0.138 inch	
9 ... 11 mm / 0.35 ... 0.43 inch	

Technical Data	
0.14 ... 1 (1.5) mm ² ①	24 ... 16 AWG
500 V/6 kV/3 ②	300 V, 10 A ③
I _N 13.5 A ③	300 V, 10 A ④
Terminal block width: 3.5 mm / 0.138 inch	
9 ... 11 mm / 0.35 ... 0.43 inch	

Technical Data	
0.14 ... 1 (1.5) mm ² ①	24 ... 16 AWG
500 V/6 kV/3 ②	300 V, 10 A ③
I _N 13.5 A ③	300 V, 10 A ④
Terminal block width: 3.5 mm / 0.138 inch	
9 ... 11 mm / 0.35 ... 0.43 inch	

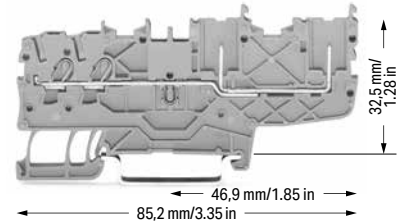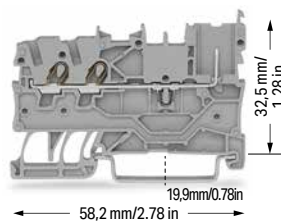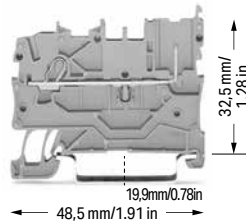

1-conductor/1-pin carrier terminal block		
Color	Item No.	Pack. Unit
○ gray	2020-1201	50
● blue	2020-1204	50

2-conductor/1-pin carrier terminal block		
Color	Item No.	Pack. Unit
○ gray	2020-1301	50
● blue	2020-1304	50

2-conductor/2-pin carrier terminal block		
Color	Item No.	Pack. Unit
○ gray	2020-1401	50
● blue	2020-1404	50

1-conductor/1-pin ground carrier terminal block		
Color	Item No.	Pack. Unit
● green-yellow	2020-1207	50

2-conductor/1-pin ground carrier terminal block		
Color	Item No.	Pack. Unit
● green-yellow	2020-1307	50

2-conductor/2-pin ground carrier terminal block		
Color	Item No.	Pack. Unit
● green-yellow	2020-1407	50

Accessories; item-specific			
End and intermediate plate; 1 mm thick			
orange	2020-1292	100 (25)	
gray	2020-1291	100 (25)	

Accessories; item-specific			
End and intermediate plate; 1 mm thick			
orange	2020-1392	100 (25)	
gray	2020-1391	100 (25)	

Accessories; item-specific			
End and intermediate plate; 1 mm thick			
orange	2020-1492	100 (25)	
gray	2020-1491	100 (25)	

Accessories; 2020 Series

Appropriate marking systems: WMB/WMB Inline/Marking strips

Push-in type jumper bar; insulated; I _N 14 A; light gray			
	2-way	2000-402	25
	3-way	2000-403	25
	4-way	2000-404	25
	5-way	2000-405	25
	6-way	2000-406	25
	7-way	2000-407	25
	8-way	2000-408	25
	9-way	2000-409	25
	10-way	2000-410	25

Delta jumper; insulated; I _N = I _N terminal block; light gray			
	1-2 3-4 5-6	2000-406/020-000	25

Star point jumper; insulated; I _N = I _N terminal block; light gray			
	1-3-5	2000-405/011-000	25

Test plug adapter; for 4 mm Ø test plug			
	gray	2009-174	100 (25)

Push-in type jumper bar; insulated; I _N 14 A; light gray			
	1 to 3	2000-433	25
	1 to 4	2000-434	25
	1 to 5	2000-435	25
	1 to 6	2000-436	25
	1 to 7	2000-437	25
	1 to 8	2000-438	25
	1 to 9	2000-439	25
	1 to 10	2000-440	25

Push-in type wire jumper; insulated; 0.75 mm ² conductor cross-section; I _N 9 A			
	L = 60 mm	2009-402	100 (10)
	L = 110 mm	2009-404	100 (10)
	L = 250 mm	2009-406	100 (10)

Banana plug; for 4 mm socket diameter; color mixed; 10 x orange, white, black, blue, yellow; max. 42 V			
		215-111	50

Protective warning marker; with black high-voltage symbol; for 5 terminal blocks			
	yellow	2000-115	100 (25)

Carrier with 6 coding pins; for coding female plugs			
	orange	2020-100	100 (25)

Testing tap; for max. 2.5 mm ²			
	gray	2009-182	100 (25)

1-conductor female plug			
	gray	2020-102	100

2-conductor female plug			
	gray	2020-202	100

Test pin; 1 mm Ø			
		859-500	1