


Data sheet | Item number: 2002-880/1000-541

Component plug; 2-pole; LED (red); 10.4 mm wide; Operating temperature 85°C max.



2002-880/1000-541

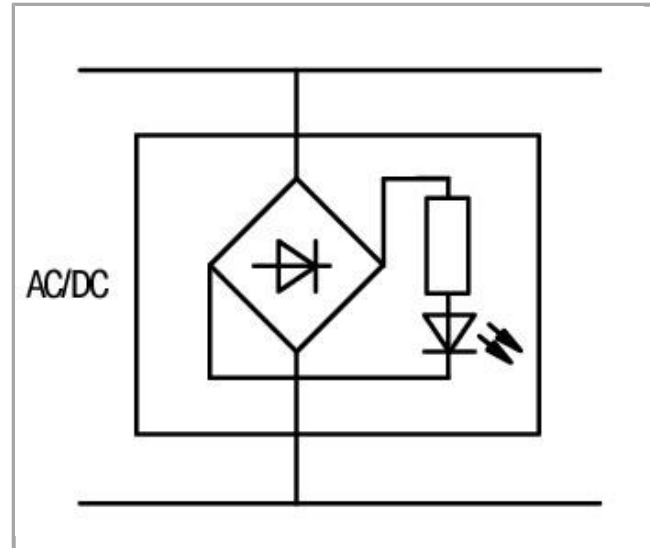

RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

## Data

### Electrical data

#### Ratings per IEC/EN 60664-1

Rated current 0.003 A

### Geometrical Data

Width 10.4 mm / 0.409 inch

## Mechanical data

Marking level	Center marking
---------------	----------------

## Material Data




Color	gray
Fire load	0.139 MJ
Weight	4.1 g

## Commercial data






Product Group	22 (TOPJOB S)
Country of origin	DE
GTIN	4045454913939
Customs Tariff No.	85369010000
















## Compatible products

### clamps









	<b>Item no.: 2002-1201</b> 2-conductor through terminal block; 2.5 mm <sup>2</sup> ; suitable for Ex e II applications; side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®	2002-1201
	<b>Item no.: 2002-1301</b> 3-conductor through terminal block; 2.5 mm <sup>2</sup> ; suitable for Ex e II applications; side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®	2002-1301
	<b>Item no.: 2002-1401</b> 4-conductor through terminal block; 2.5 mm <sup>2</sup> ; suitable for Ex e II applications; side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®	2002-1401

### Marking accessories

	<b>Item no.: 2009-110</b> Marking strips; on reel; not stretchable; plain; snap-on type	2009-110
	<b>Item no.: 2009-115</b> WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115
	<b>Item no.: 2009-115/000-002</b> WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115 /000-002
	<b>Item no.: 2009-115/000-006</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115 /000-006
	<b>Item no.: 2009-115/000-007</b> WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115 /000-007

	<b>Item no.: 2009-115/000-012</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-012	2009-115
	<b>Item no.: 2009-115/000-017</b> WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-017	2009-115
	<b>Item no.: 2009-115/000-023</b> WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-023	2009-115
	<b>Item no.: 2009-115/000-024</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-024	2009-115
	<b>Item no.: 793-501</b> WMB marking card; as card; not stretchable; plain; snap-on type		793-501
	<b>Item no.: 793-501/000-002</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-002	793-501
	<b>Item no.: 793-501/000-005</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-005	793-501
	<b>Item no.: 793-501/000-006</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-006	793-501
	<b>Item no.: 793-501/000-007</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-007	793-501
	<b>Item no.: 793-501/000-012</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-012	793-501
	<b>Item no.: 793-501/000-017</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-017	793-501
	<b>Item no.: 793-501/000-023</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-023	793-501
	<b>Item no.: 793-501/000-024</b> WMB marking card; as card; not stretchable; plain; snap-on type	/000-024	793-501
	<b>Item no.: 793-5501</b> WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type		793-5501
	<b>Item no.: 793-5501/000-002</b> WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type	/000-002	793-5501



	<p><b>Item no.: 793-5501/000-005</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-005	793-5501
	<p><b>Item no.: 793-5501/000-006</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-006	793-5501
	<p><b>Item no.: 793-5501/000-007</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-007	793-5501
	<p><b>Item no.: 793-5501/000-012</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-012	793-5501
	<p><b>Item no.: 793-5501/000-014</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-014	793-5501
	<p><b>Item no.: 793-5501/000-017</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-017	793-5501
	<p><b>Item no.: 793-5501/000-023</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-023	793-5501
	<p><b>Item no.: 793-5501/000-024</b>                  WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type</p>	/000-024	793-5501

**Downloads**

**Documentation**

**Bid Text**

2002-880/1000-541	docx 14.8 kB	Download
-------------------	-----------------	----------

**Additional Information**

	pdf 2.1 MB	Download
--	---------------	----------

**CAD/CAE - Smart Data**

**CAD data**

3D Download 2002-880/1000-541	URL	Download
-------------------------------	-----	----------



Subject to changes.

---