


Data sheet | Item number: 2003-499

Test plug adapter N/L; for 2003-6641 and 2003-6640 Multilevel Installation

Terminal Blocks; for vertical test slot; 2-pole



2003-499

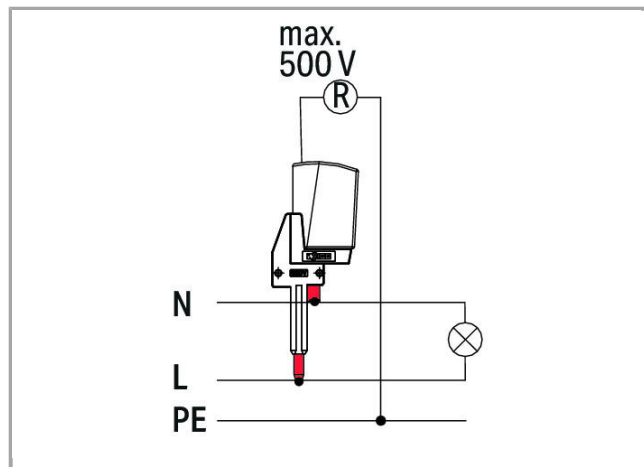



RoHS 
 Compliant


Color: **Data****Electrical data****Ratings per IEC/EN 60664-1**

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	16 A

Connection data

Connection technology	CAGE CLAMP®
Solid conductor	0.5 ... 2.5 mm ² / 20 ... 16 AWG
Stranded conductor	0.5 ... 1.5 mm ² / 20 ... 16 AWG
Fine-stranded conductor	0.5 ... 2.5 mm ² / 20 ... 16 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 inch
Total number of connection points	1
Total number of potentials	1
Type of wiring	Side-entry wiring

Material Data

Color	gray
Fire load	0.065 MJ
Weight	3.328 g

Commercial data

Product Group	22 (TOPJOB S)
Country of origin	DE
GTIN	4050821322115
Customs Tariff No.	85366990990

Downloads**Documentation****Bid Text**

2003-499

doc

Download



24.1 kB

Additional Information

pdf
2.1 MB

[Download](#)

Subject to changes.
