



Data sheet | Item number: 2020-1301

2-conductor/1-pin carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5;

Push-in CAGE CLAMP®



2020-1301

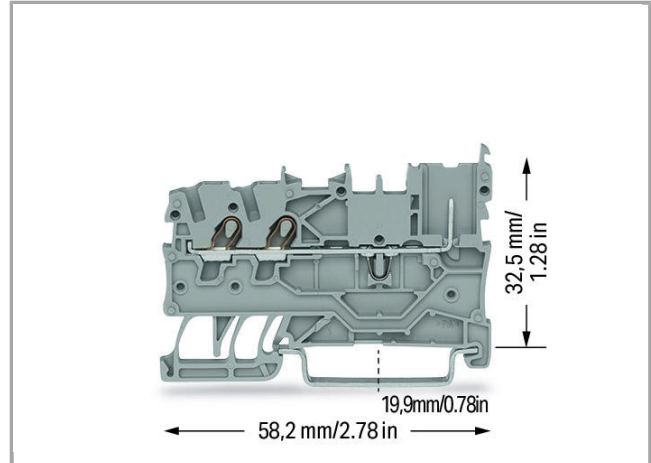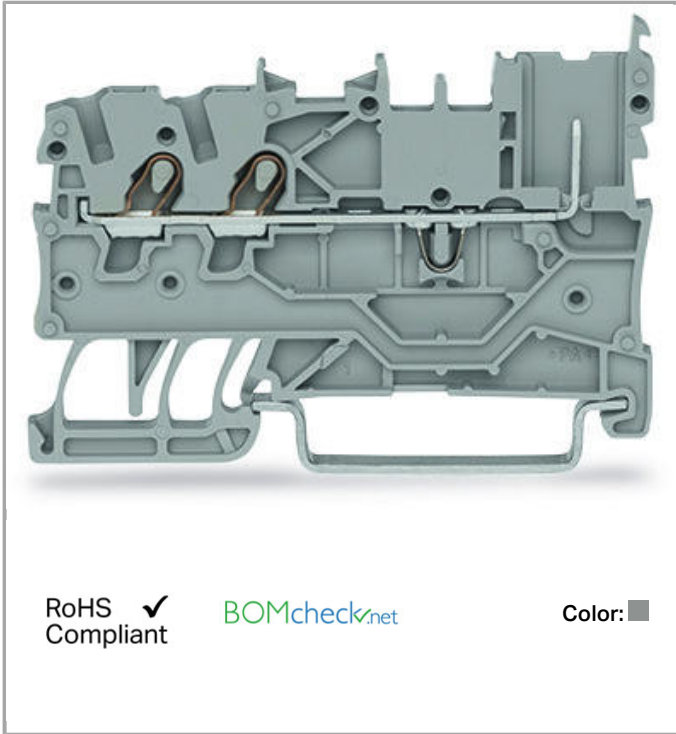

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	13.5 A

Approvals per UL 1059

Rated voltage UL (Use Group B)	300 V
Rated current UL (Use Group B)	15 A
Rated voltage UL (Use Group C)	300 V
Rated current UL (Use Group C)	15 A
Rated voltage UL (Use Group D)	300 V
Rated current UL (Use Group D)	15 A

Approvals per CSA

Rated voltage CSA (Use Group B)	300 V
---------------------------------	-------

Rated current CSA (Use Group B)	10 A
Rated voltage CSA (Use Group C)	300 V
Rated current CSA (Use Group C)	10 A

Connection data

Connection technology	Push-in CAGE CLAMP®
Number of connection points (connection type)	2
Actuation type	Open Tool Slot Push-in
Connectable conductor materials	Copper
Nominal cross section	1 mm ²
Solid conductor	0.14 ... 1.5 mm ² / 24 ... 16 AWG
Solid conductor, push-in termination	0.5 ... 1.5 mm ² / 20 ... 16 AWG
Fine-stranded conductor	0.14 ... 1.5 mm ² / 24 ... 16 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 inch
Number of connection points	1
Note (conductor cross-section)	Depending on the conductor characteristic, a conductor with a smaller cross section can also be inserted via push-in termination.
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	3.5 mm / 0.138 inch
Height from upper-edge of DIN-35 rail	32.5 mm / 1.28 inch
Depth	58.2 mm / 2.291 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center/side marking

Material Data





Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0 MJ
Weight	4.51 g

Commercial data



Country of origin	CN
GTIN	4055143288125
Customs Tariff No.	85366990990

Approvals / Certificates

Country specific Approvals















Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60947	NTR NL 7617
	CSA DEKRA Certification B.V.	C22.2 No. 158	2516073
	CSA DEKRA Certification B.V.	C22.2 No. 158	2516073
	KEMA/KEUR DEKRA Certification B.V.	EN 60947	71- 100670

UL-Approvals


 


 
 


Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 1059	E45172
	UL Underwriters Laboratories Inc.	UL 1059	E45172

Compatible products




Marking accessories

	Item no.: 2009-110 Marking strips; on reel; not stretchable; plain; snap-on type	2009-110
	Item no.: 2009-113 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113
	Item no.: 2009-113/000-002 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-002
	Item no.: 2009-113/000-005 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-005
	Item no.: 2009-113/000-006 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-006
	Item no.: 2009-113/000-007 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-007
	Item no.: 2009-113/000-012 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-012
	Item no.: 2009-113/000-017 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-017
	Item no.: 2009-113/000-023 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-023
	Item no.: 2009-113/000-024 WMB-Inline; for Smart Printer; on reel; plain; snap-on type	2009-113 /000-024
	Item no.: 793-3501 WMB marking card; as card; plain; snap-on type	793-3501
check		
	Item no.: 2009-174 Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks	2009-174
	Item no.: 2009-182 Testing tap; for max. 2.5 mm ² ; tool-free connection for individual test wires 0.08 - 2.5 mm	2009-182
	Item no.: 859-500 Test pin; 1 mm Ø; with solder connection for test wire	859-500



Carrier rail









 
	Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	210-112
	Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	210-113
	Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	210-114
	Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	210-115
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-118
	Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	210-196
	Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	210-197
	Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-198





 





 

 
ferrule



 

 


 

 
	Item no.: 216-241 Ferrule; Sleeve for 0.5 mm ² / 20 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	216-241
	Item no.: 216-242 Ferrule; Sleeve for 0.75 mm ² / 18 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	216-242
	Item no.: 216-243 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	216-243



 

 


 

 
Female plug



 

 


 

	Item no.: 2020-102 1-conductor female plug; 1.5 mm ² ; 2-pole	2020-102
	Item no.: 2020-102/122-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 2-pole	2020-102 / 122-000
	Item no.: 2020-102/132-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 2-pole	2020-102 / 132-000
	Item no.: 2020-102/142-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 2-pole	2020-102 / 142-000
	Item no.: 2020-103 1-conductor female plug; 1.5 mm ² ; 3-pole	2020-103

 




 



	Item no.: 2020-103/000-036 1-conductor female plug; 1.5 mm ² ; 3-pole	2020-103
		/000-036
	Item no.: 2020-103/000-037 1-conductor female plug; 1.5 mm ² ; 3-pole	2020-103
		/000-037
	Item no.: 2020-103/000-038 1-conductor female plug; 1.5 mm ² ; 3-pole	2020-103
		/000-038
	Item no.: 2020-103/000-039 1-conductor female plug; 1.5 mm ² ; 3-pole	2020-103
		/000-039
	Item no.: 2020-103/122-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 3-pole	2020-103
		/122-000
	Item no.: 2020-103/132-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 3-pole	2020-103
		/132-000
	Item no.: 2020-103/142-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 3-pole	2020-103
		/142-000
	Item no.: 2020-104 1-conductor female plug; 1.5 mm ² ; 4-pole	2020-104
	Item no.: 2020-104/000-036 1-conductor female plug; 1.5 mm ² ; 4-pole	2020-104
		/000-036
	Item no.: 2020-104/000-037 1-conductor female plug; 1.5 mm ² ; 4-pole	2020-104
		/000-037
	Item no.: 2020-104/000-038 1-conductor female plug; 1.5 mm ² ; 4-pole	2020-104
		/000-038
	Item no.: 2020-104/000-039 1-conductor female plug; 1.5 mm ² ; 4-pole	2020-104
		/000-039
	Item no.: 2020-104/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 4-pole	2020-104
		/124-000
	Item no.: 2020-104/133-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 4-pole	2020-104
		/133-000
	Item no.: 2020-104/143-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 4-pole	2020-104
		/143-000







 

	Item no.: 2020-105 1-conductor female plug; 1.5 mm ² ; 5-pole		2020-105
	Item no.: 2020-105/000-036 1-conductor female plug; 1.5 mm ² ; 5-pole	/000-036	2020-105
	Item no.: 2020-105/000-037 1-conductor female plug; 1.5 mm ² ; 5-pole	/000-037	2020-105
	Item no.: 2020-105/000-038 1-conductor female plug; 1.5 mm ² ; 5-pole	/000-038	2020-105
	Item no.: 2020-105/000-039 1-conductor female plug; 1.5 mm ² ; 5-pole	/000-039	2020-105
	Item no.: 2020-105/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 5-pole	/124-000	2020-105
	Item no.: 2020-105/133-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 5-pole	/133-000	2020-105
	Item no.: 2020-105/143-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 5-pole	/143-000	2020-105
	Item no.: 2020-106 1-conductor female plug; 1.5 mm ² ; 6-pole		2020-106
	Item no.: 2020-106/000-036 1-conductor female plug; 1.5 mm ² ; 6-pole	/000-036	2020-106
	Item no.: 2020-106/000-037 1-conductor female plug; 1.5 mm ² ; 6-pole	/000-037	2020-106
	Item no.: 2020-106/000-038 1-conductor female plug; 1.5 mm ² ; 6-pole	/000-038	2020-106
	Item no.: 2020-106/000-039 1-conductor female plug; 1.5 mm ² ; 6-pole	/000-039	2020-106
	Item no.: 2020-106/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 6-pole	/124-000	2020-106
	Item no.: 2020-106/133-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 6-pole	/133-000	2020-106





 




 
	Item no.: 2020-106/143-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 6-pole	/ 143-000	2020-106
	Item no.: 2020-107 1-conductor female plug; 1.5 mm ² ; 7-pole		2020-107
	Item no.: 2020-107/000-036 1-conductor female plug; 1.5 mm ² ; 7-pole	/ 000-036	2020-107
	Item no.: 2020-107/000-037 1-conductor female plug; 1.5 mm ² ; 7-pole	/ 000-037	2020-107
	Item no.: 2020-107/000-038 1-conductor female plug; 1.5 mm ² ; 7-pole	/ 000-038	2020-107
	Item no.: 2020-107/000-039 1-conductor female plug; 1.5 mm ² ; 7-pole	/ 000-039	2020-107
	Item no.: 2020-107/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 7-pole	/ 124-000	2020-107
	Item no.: 2020-107/134-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 7-pole	/ 134-000	2020-107
	Item no.: 2020-107/144-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 7-pole	/ 144-000	2020-107
	Item no.: 2020-108 1-conductor female plug; 1.5 mm ² ; 8-pole		2020-108
	Item no.: 2020-108/000-036 1-conductor female plug; 1.5 mm ² ; 8-pole	/ 000-036	2020-108
	Item no.: 2020-108/000-037 1-conductor female plug; 1.5 mm ² ; 8-pole	/ 000-037	2020-108
	Item no.: 2020-108/000-038 1-conductor female plug; 1.5 mm ² ; 8-pole	/ 000-038	2020-108
	Item no.: 2020-108/000-039 1-conductor female plug; 1.5 mm ² ; 8-pole	/ 000-039	2020-108
	Item no.: 2020-108/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 8-pole	/ 124-000	2020-108





 
 




 

	Item no.: 2020-108/134-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 8-pole		2020-108
		/ 134-000	
	Item no.: 2020-108/144-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 8-pole		2020-108
		/ 144-000	
	Item no.: 2020-109 1-conductor female plug; 1.5 mm ² ; 9-pole		2020-109
	Item no.: 2020-109/000-036 1-conductor female plug; 1.5 mm ² ; 9-pole		2020-109
		/ 000-036	
	Item no.: 2020-109/000-037 1-conductor female plug; 1.5 mm ² ; 9-pole		2020-109
		/ 000-037	
	Item no.: 2020-109/000-038 1-conductor female plug; 1.5 mm ² ; 9-pole		2020-109
		/ 000-038	
	Item no.: 2020-109/000-039 1-conductor female plug; 1.5 mm ² ; 9-pole		2020-109
		/ 000-039	
	Item no.: 2020-109/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 9-pole		2020-109
		/ 124-000	
	Item no.: 2020-109/134-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 9-pole		2020-109
		/ 134-000	
	Item no.: 2020-109/144-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 9-pole		2020-109
		/ 144-000	
	Item no.: 2020-110 1-conductor female plug; 1.5 mm ² ; 10-pole		2020-110
	Item no.: 2020-110/000-036 1-conductor female plug; 1.5 mm ² ; 10-pole		2020-110
		/ 000-036	
	Item no.: 2020-110/000-037 1-conductor female plug; 1.5 mm ² ; 10-pole		2020-110
		/ 000-037	
	Item no.: 2020-110/000-038 1-conductor female plug; 1.5 mm ² ; 10-pole		2020-110
		/ 000-038	
	Item no.: 2020-110/000-039 1-conductor female plug; 1.5 mm ² ; 10-pole		2020-110
		/ 000-039	







 



	Item no.: 2020-110/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 10-pole	/ 125-000	2020-110
	Item no.: 2020-110/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 10-pole	/ 135-000	2020-110
	Item no.: 2020-110/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 10-pole	/ 145-000	2020-110
	Item no.: 2020-111 1-conductor female plug; 1.5 mm ² ; 11-pole		2020-111
	Item no.: 2020-111/000-036 1-conductor female plug; 1.5 mm ² ; 11-pole	/ 000-036	2020-111
	Item no.: 2020-111/000-037 1-conductor female plug; 1.5 mm ² ; 11-pole	/ 000-037	2020-111
	Item no.: 2020-111/000-038 1-conductor female plug; 1.5 mm ² ; 11-pole	/ 000-038	2020-111
	Item no.: 2020-111/000-039 1-conductor female plug; 1.5 mm ² ; 11-pole	/ 000-039	2020-111
	Item no.: 2020-111/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 11-pole	/ 125-000	2020-111
	Item no.: 2020-111/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 11-pole	/ 135-000	2020-111
	Item no.: 2020-111/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 11-pole	/ 145-000	2020-111
	Item no.: 2020-112 1-conductor female plug; 1.5 mm ² ; 12-pole		2020-112
	Item no.: 2020-112/000-036 1-conductor female plug; 1.5 mm ² ; 12-pole	/ 000-036	2020-112
	Item no.: 2020-112/000-037 1-conductor female plug; 1.5 mm ² ; 12-pole	/ 000-037	2020-112
	Item no.: 2020-112/000-038 1-conductor female plug; 1.5 mm ² ; 12-pole	/ 000-038	2020-112







 
 

	Item no.: 2020-112/000-039 1-conductor female plug; 1.5 mm ² ; 12-pole	/000-039	2020-112
	Item no.: 2020-112/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 12-pole	/125-000	2020-112
	Item no.: 2020-112/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 12-pole	/135-000	2020-112
	Item no.: 2020-112/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 12-pole	/145-000	2020-112
	Item no.: 2020-113 1-conductor female plug; 1.5 mm ² ; 13-pole		2020-113
	Item no.: 2020-113/000-036 1-conductor female plug; 1.5 mm ² ; 13-pole	/000-036	2020-113
	Item no.: 2020-113/000-037 1-conductor female plug; 1.5 mm ² ; 13-pole	/000-037	2020-113
	Item no.: 2020-113/000-038 1-conductor female plug; 1.5 mm ² ; 13-pole	/000-038	2020-113
	Item no.: 2020-113/000-039 1-conductor female plug; 1.5 mm ² ; 13-pole	/000-039	2020-113
	Item no.: 2020-113/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 13-pole	/125-000	2020-113
	Item no.: 2020-113/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 13-pole	/135-000	2020-113
	Item no.: 2020-113/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 13-pole	/145-000	2020-113
	Item no.: 2020-114 1-conductor female plug; 1.5 mm ² ; 14-pole		2020-114
	Item no.: 2020-114/000-036 1-conductor female plug; 1.5 mm ² ; 14-pole	/000-036	2020-114
	Item no.: 2020-114/000-037 1-conductor female plug; 1.5 mm ² ; 14-pole	/000-037	2020-114



 




 

	Item no.: 2020-114/000-038 1-conductor female plug; 1.5 mm ² ; 14-pole	/000-038	2020-114
	Item no.: 2020-114/000-039 1-conductor female plug; 1.5 mm ² ; 14-pole	/000-039	2020-114
	Item no.: 2020-114/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 14-pole	/125-000	2020-114
	Item no.: 2020-114/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 14-pole	/135-000	2020-114
	Item no.: 2020-114/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 14-pole	/145-000	2020-114
	Item no.: 2020-115 1-conductor female plug; 1.5 mm ² ; 15-pole		2020-115
	Item no.: 2020-115/000-036 1-conductor female plug; 1.5 mm ² ; 15-pole	/000-036	2020-115
	Item no.: 2020-115/000-037 1-conductor female plug; 1.5 mm ² ; 15-pole	/000-037	2020-115
	Item no.: 2020-115/000-038 1-conductor female plug; 1.5 mm ² ; 15-pole	/000-038	2020-115
	Item no.: 2020-115/000-039 1-conductor female plug; 1.5 mm ² ; 15-pole	/000-039	2020-115
	Item no.: 2020-115/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 15-pole	/125-000	2020-115
	Item no.: 2020-115/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 15-pole	/135-000	2020-115
	Item no.: 2020-115/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 15-pole	/145-000	2020-115
	Item no.: 2020-202 2-conductor female connector; 1.5 mm ² ; 2-pole		2020-202
	Item no.: 2020-202/122-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 2-pole	/122-000	2020-202




 





	Item no.: 2020-202/132-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 2-pole		2020-202
		/ 132-000	
	Item no.: 2020-202/142-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 2-pole		2020-202
		/ 142-000	
	Item no.: 2020-203 2-conductor female connector; 1.5 mm ² ; 3-pole		2020-203
	Item no.: 2020-203/000-036 2-conductor female connector; 1.5 mm ² ; 3-pole		2020-203
		/ 000-036	
	Item no.: 2020-203/000-037 2-conductor female connector; 1.5 mm ² ; 3-pole		2020-203
		/ 000-037	
	Item no.: 2020-203/000-038 2-conductor female connector; 1.5 mm ² ; 3-pole		2020-203
		/ 000-038	
	Item no.: 2020-203/000-039 2-conductor female connector; 1.5 mm ² ; 3-pole		2020-203
		/ 000-039	
	Item no.: 2020-203/122-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 3-pole		2020-203
		/ 122-000	
	Item no.: 2020-203/132-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 3-pole		2020-203
		/ 132-000	
	Item no.: 2020-203/142-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 3-pole		2020-203
		/ 142-000	
	Item no.: 2020-204 2-conductor female connector; 1.5 mm ² ; 4-pole		2020-204
	Item no.: 2020-204/000-036 2-conductor female connector; 1.5 mm ² ; 4-pole		2020-204
		/ 000-036	
	Item no.: 2020-204/000-037 2-conductor female connector; 1.5 mm ² ; 4-pole		2020-204
		/ 000-037	
	Item no.: 2020-204/000-038 2-conductor female connector; 1.5 mm ² ; 4-pole		2020-204
		/ 000-038	
	Item no.: 2020-204/000-039 2-conductor female connector; 1.5 mm ² ; 4-pole		2020-204
		/ 000-039	




 






	Item no.: 2020-204/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 4-pole	/ 124-000	2020-204
	Item no.: 2020-204/133-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 4-pole	/ 133-000	2020-204
	Item no.: 2020-204/143-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 4-pole	/ 143-000	2020-204
	Item no.: 2020-205 2-conductor female connector; 1.5 mm ² ; 5-pole		2020-205
	Item no.: 2020-205/000-036 2-conductor female connector; 1.5 mm ² ; 5-pole	/ 000-036	2020-205
	Item no.: 2020-205/000-037 2-conductor female connector; 1.5 mm ² ; 5-pole	/ 000-037	2020-205
	Item no.: 2020-205/000-038 2-conductor female connector; 1.5 mm ² ; 5-pole	/ 000-038	2020-205
	Item no.: 2020-205/000-039 2-conductor female connector; 1.5 mm ² ; 5-pole	/ 000-039	2020-205
	Item no.: 2020-205/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 5-pole	/ 124-000	2020-205
	Item no.: 2020-205/133-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 5-pole	/ 133-000	2020-205
	Item no.: 2020-205/143-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 5-pole	/ 143-000	2020-205
	Item no.: 2020-206 2-conductor female connector; 1.5 mm ² ; 6-pole		2020-206
	Item no.: 2020-206/000-036 2-conductor female connector; 1.5 mm ² ; 6-pole	/ 000-036	2020-206
	Item no.: 2020-206/000-037 2-conductor female connector; 1.5 mm ² ; 6-pole	/ 000-037	2020-206
	Item no.: 2020-206/000-038 2-conductor female connector; 1.5 mm ² ; 6-pole	/ 000-038	2020-206

	Item no.: 2020-206/000-039 2-conductor female connector; 1.5 mm ² ; 6-pole	/000-039	2020-206
	Item no.: 2020-206/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 6-pole	/124-000	2020-206
	Item no.: 2020-206/133-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 6-pole	/133-000	2020-206
	Item no.: 2020-206/143-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 6-pole	/143-000	2020-206
	Item no.: 2020-207 2-conductor female connector; 1.5 mm ² ; 7-pole		2020-207
	Item no.: 2020-207/000-036 2-conductor female connector; 1.5 mm ² ; 7-pole	/000-036	2020-207
	Item no.: 2020-207/000-037 2-conductor female connector; 1.5 mm ² ; 7-pole	/000-037	2020-207
	Item no.: 2020-207/000-038 2-conductor female connector; 1.5 mm ² ; 7-pole	/000-038	2020-207
	Item no.: 2020-207/000-039 2-conductor female connector; 1.5 mm ² ; 7-pole	/000-039	2020-207
	Item no.: 2020-207/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 7-pole	/124-000	2020-207
	Item no.: 2020-207/134-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 7-pole	/134-000	2020-207
	Item no.: 2020-207/144-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 7-pole	/144-000	2020-207
	Item no.: 2020-208 2-conductor female connector; 1.5 mm ² ; 8-pole		2020-208
	Item no.: 2020-208/000-036 2-conductor female connector; 1.5 mm ² ; 8-pole	/000-036	2020-208
	Item no.: 2020-208/000-037 2-conductor female connector; 1.5 mm ² ; 8-pole	/000-037	2020-208

	Item no.: 2020-208/000-038 2-conductor female connector; 1.5 mm ² ; 8-pole	/000-038	2020-208
	Item no.: 2020-208/000-039 2-conductor female connector; 1.5 mm ² ; 8-pole	/000-039	2020-208
	Item no.: 2020-208/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 8-pole	/124-000	2020-208
	Item no.: 2020-208/134-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 8-pole	/134-000	2020-208
	Item no.: 2020-208/144-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 8-pole	/144-000	2020-208
	Item no.: 2020-209 2-conductor female connector; 1.5 mm ² ; 9-pole		2020-209
	Item no.: 2020-209/000-036 2-conductor female connector; 1.5 mm ² ; 9-pole	/000-036	2020-209
	Item no.: 2020-209/000-037 2-conductor female connector; 1.5 mm ² ; 9-pole	/000-037	2020-209
	Item no.: 2020-209/000-038 2-conductor female connector; 1.5 mm ² ; 9-pole	/000-038	2020-209
	Item no.: 2020-209/000-039 2-conductor female connector; 1.5 mm ² ; 9-pole	/000-039	2020-209
	Item no.: 2020-209/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 9-pole	/124-000	2020-209
	Item no.: 2020-209/134-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 9-pole	/134-000	2020-209
	Item no.: 2020-209/144-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 9-pole	/144-000	2020-209
	Item no.: 2020-210 2-conductor female connector; 1.5 mm ² ; 10-pole		2020-210
	Item no.: 2020-210/000-036 2-conductor female connector; 1.5 mm ² ; 10-pole	/000-036	2020-210

	Item no.: 2020-210/000-037 2-conductor female connector; 1.5 mm ² ; 10-pole	/000-037	2020-210
	Item no.: 2020-210/000-038 2-conductor female connector; 1.5 mm ² ; 10-pole	/000-038	2020-210
	Item no.: 2020-210/000-039 2-conductor female connector; 1.5 mm ² ; 10-pole	/000-039	2020-210
	Item no.: 2020-210/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 10-pole	/125-000	2020-210
	Item no.: 2020-210/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 10-pole	/135-000	2020-210
	Item no.: 2020-210/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 10-pole	/145-000	2020-210
	Item no.: 2020-211 2-conductor female connector; 1.5 mm ² ; 11-pole		2020-211
	Item no.: 2020-211/000-036 2-conductor female connector; 1.5 mm ² ; 11-pole	/000-036	2020-211
	Item no.: 2020-211/000-037 2-conductor female connector; 1.5 mm ² ; 11-pole	/000-037	2020-211
	Item no.: 2020-211/000-038 2-conductor female connector; 1.5 mm ² ; 11-pole	/000-038	2020-211
	Item no.: 2020-211/000-039 2-conductor female connector; 1.5 mm ² ; 11-pole	/000-039	2020-211
	Item no.: 2020-211/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 11-pole	/125-000	2020-211
	Item no.: 2020-211/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 11-pole	/135-000	2020-211
	Item no.: 2020-211/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 11-pole	/145-000	2020-211
	Item no.: 2020-212 2-conductor female connector; 1.5 mm ² ; 12-pole		2020-212

	Item no.: 2020-212/000-036 2-conductor female connector; 1.5 mm ² ; 12-pole	/000-036	2020-212
	Item no.: 2020-212/000-037 2-conductor female connector; 1.5 mm ² ; 12-pole	/000-037	2020-212
	Item no.: 2020-212/000-038 2-conductor female connector; 1.5 mm ² ; 12-pole	/000-038	2020-212
	Item no.: 2020-212/000-039 2-conductor female connector; 1.5 mm ² ; 12-pole	/000-039	2020-212
	Item no.: 2020-212/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 12-pole	/125-000	2020-212
	Item no.: 2020-212/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 12-pole	/135-000	2020-212
	Item no.: 2020-212/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 12-pole	/145-000	2020-212
	Item no.: 2020-213 2-conductor female connector; 1.5 mm ² ; 13-pole		2020-213
	Item no.: 2020-213/000-036 2-conductor female connector; 1.5 mm ² ; 13-pole	/000-036	2020-213
	Item no.: 2020-213/000-037 2-conductor female connector; 1.5 mm ² ; 13-pole	/000-037	2020-213
	Item no.: 2020-213/000-038 2-conductor female connector; 1.5 mm ² ; 13-pole	/000-038	2020-213
	Item no.: 2020-213/000-039 2-conductor female connector; 1.5 mm ² ; 13-pole	/000-039	2020-213
	Item no.: 2020-213/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 13-pole	/125-000	2020-213
	Item no.: 2020-213/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 13-pole	/135-000	2020-213
	Item no.: 2020-213/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 13-pole	/145-000	2020-213

	Item no.: 2020-214 2-conductor female connector; 1.5 mm ² ; 14-pole		2020-214
	Item no.: 2020-214/000-036 2-conductor female connector; 1.5 mm ² ; 14-pole	/000-036	2020-214
	Item no.: 2020-214/000-037 2-conductor female connector; 1.5 mm ² ; 14-pole	/000-037	2020-214
	Item no.: 2020-214/000-038 2-conductor female connector; 1.5 mm ² ; 14-pole	/000-038	2020-214
	Item no.: 2020-214/000-039 2-conductor female connector; 1.5 mm ² ; 14-pole	/000-039	2020-214
	Item no.: 2020-214/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 14-pole	/125-000	2020-214
	Item no.: 2020-214/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 14-pole	/135-000	2020-214
	Item no.: 2020-214/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 14-pole	/145-000	2020-214
	Item no.: 2020-215 2-conductor female connector; 1.5 mm ² ; 15-pole		2020-215
	Item no.: 2020-215/000-036 2-conductor female connector; 1.5 mm ² ; 15-pole	/000-036	2020-215
	Item no.: 2020-215/000-037 2-conductor female connector; 1.5 mm ² ; 15-pole	/000-037	2020-215
	Item no.: 2020-215/000-038 2-conductor female connector; 1.5 mm ² ; 15-pole	/000-038	2020-215
	Item no.: 2020-215/000-039 2-conductor female connector; 1.5 mm ² ; 15-pole	/000-039	2020-215
	Item no.: 2020-215/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 15-pole	/125-000	2020-215
	Item no.: 2020-215/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 15-pole	/135-000	2020-215

Item no.: 2020-215/145-000		2020-215
2-conductor female connector; Strain relief plate; 1.5 mm ² ; 15-pole	/ 145-000	

tools

Item no.: 210-647		210-647
Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short		



Item no.: 210-648		210-648
Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short; angled		



Item no.: 210-719		210-719
Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm		

Coding

Item no.: 2020-100		2020-100
Carrier with 6 coding pins; for coding of female plugs; for carrier terminal blocks		

End plate

Item no.: 2020-1391		2020-
End and intermediate plate	1391	

Item no.: 2020-1392		2020-
End and intermediate plate	1392	

General accessories

Item no.: 2020-161		2020-161
Start module for 1-conductor female connector; with integrated end plate; 1.5 mm ² ; 1-pole		



Item no.: 2020-164		2020-164
Start module for 1-conductor female connector; with integrated end plate; 1.5 mm ² ; 1-pole		



Item no.: 2020-167		2020-167
Start module for 1-conductor female connector; 1.5 mm ² ; 1-pole		



Item no.: 2020-181		2020-181
End module for 1-conductor female connector; 1.5 mm ² ; 1-pole		



Item no.: 2020-184		2020-184
End module for 1-conductor female connector; 1.5 mm ² ; 1-pole		



Item no.: 2020-187		2020-187
End module for 1-conductor female connector; 1.5 mm ² ; 1-pole		



Item no.: 2020-261		2020-261
Start module for 2-conductor female connector; with integrated end plate; 1.5 mm ² ; 1-pole		



Item no.: 2020-264		2020-264
Start module for 2-conductor female connector; with integrated end plate; 1.5 mm ² ; 1-pole		







 


 


 





















Item no.: 2020-267		2020-267
Start module for 2-conductor female connector; 1.5 mm ² ; 1-pole		



















Item no.: 2020-281		2020-281
End module for 2-conductor female connector; 1.5 mm ² ; 1-pole		

Item no.: 2020-284		
--------------------	--	--

	End module for 2-conductor female connector; 1.5 mm ² ; 1-pole		2020-284
	Item no.: 2020-287 End module for 2-conductor female connector; 1.5 mm ² ; 1-pole		2020-287
Jumper			
	Item no.: 2000-402 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A		2000-402
	Item no.: 2000-402/000-005 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	/000-005	2000-402
	Item no.: 2000-402/000-006 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	/000-006	2000-402
	Item no.: 2000-402/000-018 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	/000-018	2000-402
	Item no.: 2000-403 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A		2000-403
	Item no.: 2000-403/000-005 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	/000-005	2000-403
	Item no.: 2000-403/000-006 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	/000-006	2000-403
	Item no.: 2000-404 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A		2000-404
	Item no.: 2000-404/000-005 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	/000-005	2000-404
	Item no.: 2000-404/000-006 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	/000-006	2000-404
	Item no.: 2000-405 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A		2000-405
	Item no.: 2000-405/000-005 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	/000-005	2000-405
	Item no.: 2000-405/000-006 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	/000-006	2000-405
	Item no.: 2000-405/011-000 Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block	/011-000	2000-405

	Item no.: 2000-406 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A		2000-406
	Item no.: 2000-406/000-005 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	/000-005	2000-406
	Item no.: 2000-406/000-006 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	/000-006	2000-406
	Item no.: 2000-406/020-000 Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block	/020-000	2000-406
	Item no.: 2000-407 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A		2000-407
	Item no.: 2000-407/000-005 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	/000-005	2000-407
	Item no.: 2000-407/000-006 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	/000-006	2000-407
	Item no.: 2000-408 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A		2000-408
	Item no.: 2000-408/000-005 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	/000-005	2000-408
	Item no.: 2000-408/000-006 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	/000-006	2000-408
	Item no.: 2000-409 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A		2000-409
	Item no.: 2000-409/000-005 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	/000-005	2000-409
	Item no.: 2000-409/000-006 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	/000-006	2000-409
	Item no.: 2000-410 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A		2000-410
	Item no.: 2000-410/000-005 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	/000-005	2000-410
	Item no.: 2000-410/000-006 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	/000-006	2000-410

	Item no.: 2000-433 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	2000-433
	Item no.: 2000-433/000-005 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	2000-433 /000-005
	Item no.: 2000-433/000-006 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	2000-433 /000-006
	Item no.: 2000-434 Push-in type jumper bar; insulated; from 1 to 4; Nominal current 14 A	2000-434
	Item no.: 2000-435 Push-in type jumper bar; insulated; from 1 to 5; Nominal current 14 A	2000-435
	Item no.: 2000-436 Push-in type jumper bar; insulated; from 1 to 6; Nominal current 14 A	2000-436
	Item no.: 2000-437 Push-in type jumper bar; insulated; from 1 to 7; Nominal current 14 A	2000-437
	Item no.: 2000-438 Push-in type jumper bar; insulated; from 1 to 8; Nominal current 14 A	2000-438
	Item no.: 2000-439 Push-in type jumper bar; insulated; from 1 to 9; Nominal current 14 A	2000-439
	Item no.: 2000-440 Push-in type jumper bar; insulated; from 1 to 10; Nominal current 14 A	2000-440
	Item no.: 2009-402 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²; suitable for 2000 and 2020 Series rail-mounted terminal blocks	2009-402
	Item no.: 2009-404 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²; suitable for 2000 and 2020 Series rail-mounted terminal blocks	2009-404
	Item no.: 2009-406 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²; suitable for 2000 and 2020 Series rail-mounted terminal blocks	2009-406
	Item no.: 210-103 Wire commoning chain; insulated; 50 connections	210-103
	Item no.: 210-123 Wire commoning chain; insulated; 50 connections	210-123
Protective Warning Marker		
	Item no.: 2000-115 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	2000-115

Downloads

Documentation

Bid Text



2020-1301

docx
15.5 kB

Download

CAD/CAE - Smart Data

CAD data

3D Download 2020-1301

URL

Download

Product family

X-COM S-Mini

Show all products from the family

Subject to changes.
