


Data sheet | Item number: 215-311

Banana plug; for socket 4 mm Ø

215-311

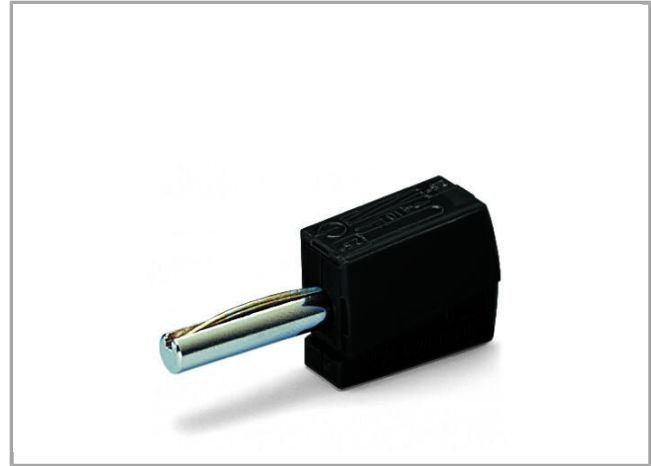

**Data****Technical Data**

Main product function	Testing accessories
Total number of potentials	1

**Electrical data**

Rated current	20 A
Test voltage	42 V

**Connection data**

Connection technology	CAGE CLAMP®
Strip length	9 ... 11 mm / 0.35 ... 0.43 inch
Total number of connection points	1
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 14 AWG
Fine-stranded conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 14 AWG

**Geometrical Data**

Abmessungen B x H x T (mm)	(8 x 15 x 40) mm
Abmessungen B x H x T (inch)	(0.315 x 0.591 x 1.575) inch



Width	8 mm / 0.315 inch
Height	15 mm / 0.591 inch
Depth	40 mm / 1.575 inch

### Material Data

Weight	3.87 g
--------	--------

### Commercial data

Product Group	2 (Terminal Block Accessories)
Country of origin	DE
GTIN	4045454293499
Customs Tariff No.	85366990990

### Downloads

#### Documentation

#### Bid Text

215-311	doc	Download
	25.1 kB	

Subject to changes.