


Data sheet | Item number: 231-662

Test plugs for female connectors; for 7.5 mm and 7.62 mm pin spacing

231-662

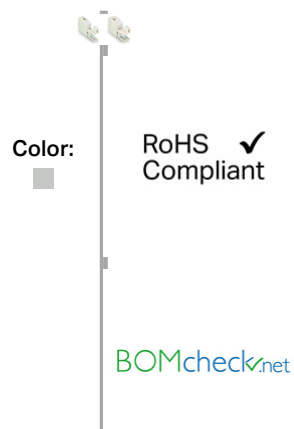

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|-------|
| Rated voltage (III / 2) | 250 V |
| Rated impulse voltage (III / 2) | 4 kV |
| Rated current | 12 A |

Connection data

| | |
|----------------------------|---------------------------------|
| Connection technology | CAGE CLAMP® |
| Strip length | 8 ... 9 mm / 0.31 ... 0.35 inch |
| Number of connection types | 1 |

Geometrical Data

| | |
|-------------|------------------------------|
| Pin spacing | 7.5/7.62 mm / 0.295/0.3 inch |
|-------------|------------------------------|

Material Data

| | |
|-----------|------------|
| Color | light gray |
| Fire load | 0.046 MJ |
| Weight | 2.138 g |

Commercial data

| | |
|---------------|------------------------|
| Product Group | 3 (Multi Conn. System) |
|---------------|------------------------|



| | |
|--------------------|---------------|
| Country of origin | DE |
| GTIN | 4044918287685 |
| Customs Tariff No. | 85366990990 |

Approvals / Certificates

Country specific Approvals

| Logo | Approval | Additional Approval Text | Certificate name |
|------|---------------------------------------|--------------------------|------------------|
| | CB DEKRA Certification B.V. | IEC 61984 | NL-39756 |

Ship Approvals

| Logo | Approval | Additional Approval Text | Certificate name |
|---|---|--------------------------|--------------------------|
|  | ABS American Bureau of Shipping | - | 14- HG1241537- PDA |
|  | DNV GL Det Norske Veritas, Germanischer Lloyd | - | TAE000016Z |

Subject to changes.