


## Data sheet | Item number: 231-902

Comb-style jumper bar; for 5 mm and 5.08 mm pin spacing; reduces conductor size to 1.5 mm



231-902

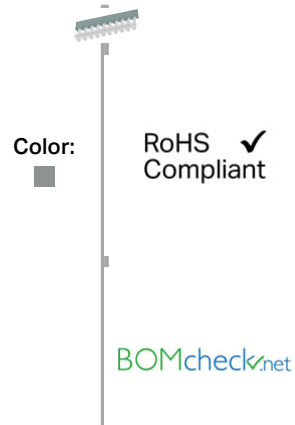

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	320 V
Rated impulse voltage (III / 2)	4 kV
Rated current	12 A

#### Connection data

No. of poles	2
Number of connection types	1

#### Geometrical Data

Pin spacing	5/5.08 mm / 0.197/0.2 inch
Width	10 mm / 0.394 inch
Depth	5 mm / 0.197 inch

#### Material Data


Color	gray
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.001 MJ
Weight	0.23 g

## Commercial data


Product Group	3 (Multi Conn. System)
Country of origin	DE
GTIN	4045454045425
Customs Tariff No.	85366990990

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>CB</b> DEKRA Certification B.V.	IEC 61984	NL-39756
	<b>KEMA/KEUR</b> DEKRA Certification B.V.	EN 61984	2190761.01

### Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>ABS</b> American Bureau of Shipping	-	14- HG1241537- PDA

## Downloads

### CAD/CAE - Smart Data

#### CAD data

3D Download 231-902	URL	Download

Subject to changes.