


Data sheet | Item number: 231-907

Comb-style jumper bar; 7-way; suitable for 231 Series female connectors;
with 5 mm pin spacing; insulated



231-907

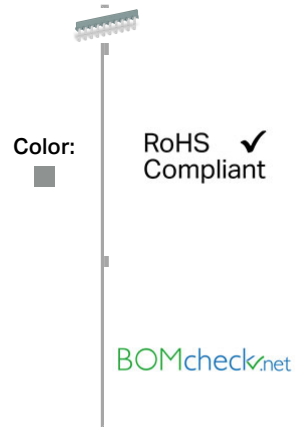

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	320 V
Rated impulse voltage (III / 2)	4 kV
Rated current	16 A

Connection data

No. of poles	7
Number of connection types	1

Geometrical Data

Pin spacing	5/5.08 mm / 0.197/0.2 inch
Width	35.3 mm / 1.39 inch
Depth	6.15 mm / 0.242 inch

Material Data

Color	gray
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.016 MJ
Weight	1.72 g



Commercial data

Product Group	3 (Multi Conn. System)
Country of origin	DE
GTIN	4045454565862
Customs Tariff No.	85366990990

Subject to changes.
