




Data sheet | Item number: 249-114

Test plug adapter; suitable for 255, 256, 257 Series PCB terminal blocks; 1-pole; Pin spacing 10 mm / 0.394 in



249-114

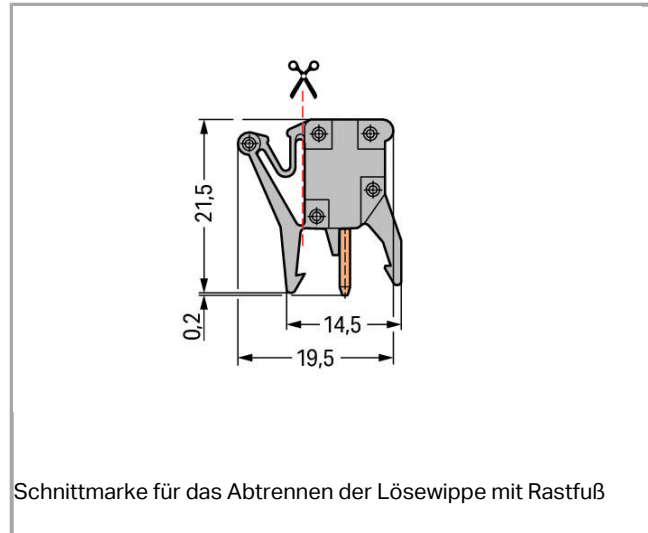

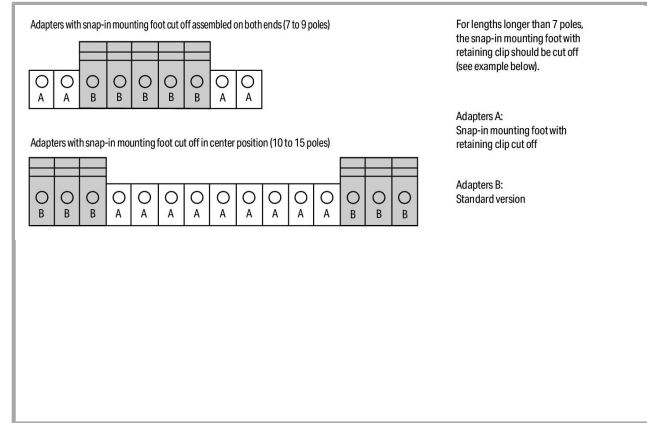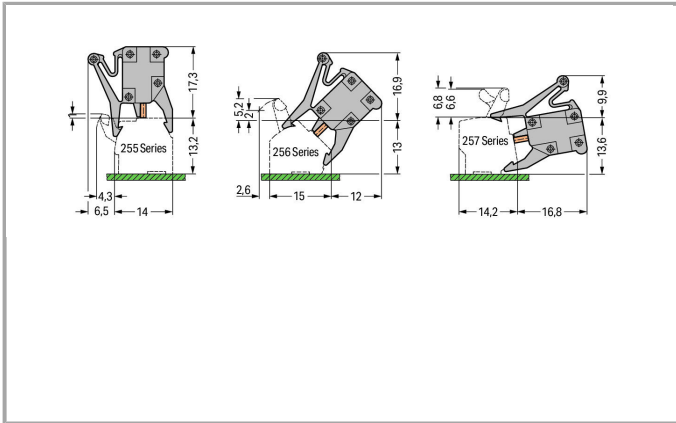

**Data**

**Electrical data**

**Ratings per IEC/EN 60664-1**

|                                 |       |
|---------------------------------|-------|
| Rated voltage (III / 2)         | 320 V |
| Rated impulse voltage (III / 2) | 4 kV  |
| Rated current                   | 6 A   |

**Connection data**

|                            |   |
|----------------------------|---|
| No. of poles               | 1 |
| Number of connection types | 1 |

**Geometrical Data**

|             |                      |
|-------------|----------------------|
| Pin spacing | 10 mm / 0.394 inch   |
| Width       | 10 mm / 0.394 inch   |
| Height      | 21.5 mm / 0.846 inch |
| Depth       | 19.5 mm / 0.768 inch |

**Material Data**

|                             |                      |
|-----------------------------|----------------------|
| Color                       | gray                 |
| Material group              | I                    |
| Insulating material         | Polyamide 66 (PA 66) |
| Flammability class per UL94 | V0                   |
| Fire load                   | 0 MJ                 |
| Weight                      | 1.661 g              |

**Environmental Requirements**

|                         |                 |
|-------------------------|-----------------|
| Limit temperature range | -60 ... +105 °C |
|-------------------------|-----------------|



**Commercial data**

|                    |                                |
|--------------------|--------------------------------|
| Product Group      | 2 (Terminal Block Accessories) |
| Country of origin  | CH                             |
| GTIN               | 4045454306854                  |
| Customs Tariff No. | 85366990990                    |

Subject to changes.

---