



## Data sheet | Item number: 272-304

Power supply connector; push-button on both sides; without snap-in mounting feet; without ground contact; 4-pole; white

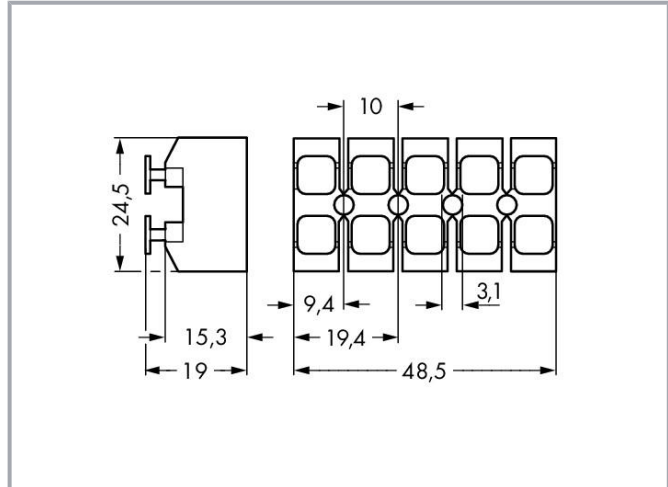

[www.wago.com/272-304](http://www.wago.com/272-304)

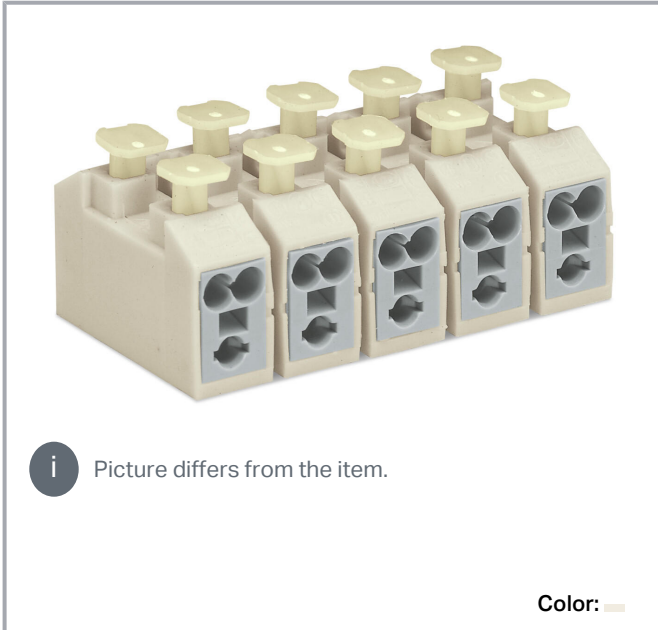

### Data

#### Electrical data

#### IEC Approvals

Ratings per	IEC/EN 60664-1
Rated voltage (III/2)	400 V
Rated surge voltage (III/2)	4 kV
Rated current	18 A
Legend (ratings)	(III / 2) ≙ Overvoltage category III / Pollution degree 2

#### Connection data

Connection technology	PUSH WIRE®
Solid conductor	0.5 ... 1.5 mm <sup>2</sup> / 20 ... 16 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 inch
Pole No.	4
Solid conductor 2	0.5 ... 2.5 mm <sup>2</sup> / 20 ... 14 AWG

Subject to changes. Please also observe the further product documentation!

WAGO Corporation  
Germantown, WI 53022  
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222  
Email: [info.us@wago.com](mailto:info.us@wago.com) | Web: [www.wago.us](http://www.wago.us)

Do you have any questions about our products?  
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.

Total number of connection points	16
Total number of potentials	4
Number of connection types	1

### Physical data

Width	38.5 mm / 1.516 inch
Height	19 mm / 0.748 inch
Depth	24.5 mm / 0.965 inch

### Material data


Color	white
Fire load	0.211 MJ
Weight	12.7 g

### Commercial data


Packaging type	bag
Country of origin	DE
GTIN	4044918439688
Customs tariff number	8536904000

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CSA DEKRA Certification B.V.	C22.2 No. 158	70048844

#### UL-Approvals




Logo	Approval	Additional Approval Text	Certificate name
	UR Underwriters Laboratories Inc.	UL 1059	20190731- E45172

Subject to changes. Please also observe the further product documentation!




## Optional accessories

### Mounting

	<b>Item no.: 271-702</b> Pins; for plate thickness 1 mm	<a href="http://www.wago.com/271-702">www.wago.com/271-702</a>
	<b>Item no.: 271-711</b> Pins; for plate thickness 1 mm	<a href="http://www.wago.com/271-711">www.wago.com/271-711</a>
	<b>Item no.: 271-712</b> Pins; for plate thickness 1.5 mm	<a href="http://www.wago.com/271-712">www.wago.com/271-712</a>

### Tools

	<b>Item no.: 249-100</b> Operating tool; for terminal blocks with snap-in ground contact	<a href="http://www.wago.com/249-100">www.wago.com/249-100</a>
---	---	--

## Downloads

### Documentation

#### Additional Information

Technical explanations	Apr 3, 2019	pdf 2.0 MB	Download
------------------------	-------------	---------------	----------

## Environmental Product Compliance

### Compliance Search

Environmental Product Compliance 272-304 Power supply connector; push-button on both sides; without snap-in mounting feet; without ground contact; 4-pole; white	URL	Download
--	-----	----------

## Installation Notes

Subject to changes. Please also observe the further product documentation!