


Data sheet | Item number: 280-801/281-420

Component plug; for carrier terminal blocks; 2-pole; with LED and recovery diode; 5 mm wide



280-801/281-420

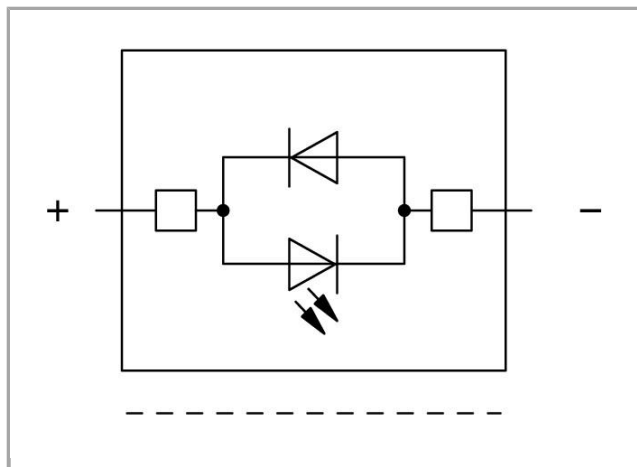

**Data**

**Electrical data**

Nominal voltage	250 V
Reverse voltage	1000 V

## Ratings per IEC/EN 60664-1

Rated current	0.5 A
---------------	-------

## Geometrical Data

Width	5 mm / 0.197 inch
-------	-------------------

## Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.068 MJ
Weight	2.972 g

## Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
Country of origin	DE
GTIN	4050821385837
Customs Tariff No.	85369010000

## Compatible products

## clamps



<b>Item no.: 280-610</b> 3-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-610
--	---------



<b>Item no.: 280-616</b> 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-616
--	---------



<b>Item no.: 280-686</b> 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-686
--	---------



<b>Item no.: 280-816</b> 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-816
--	---------



<b>Item no.: 280-916</b> 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-916
--	---------

## Downloads

## Documentation

## Bid Text

280-801/281-420

doc Download  
23.6 kB



**CAD/CAE - Smart Data**

**CAD data**

3D Download 280-801/281-420

URL

Download

---

Subject to changes.

---