


## Data sheet | Item number: 280-850/281-414

Fuse plug; with soldered miniature fuse; with indicator lamp; LED (red); DC 30  
- 65 V; 250 mA FF; 5 mm wide



280-850/281-414

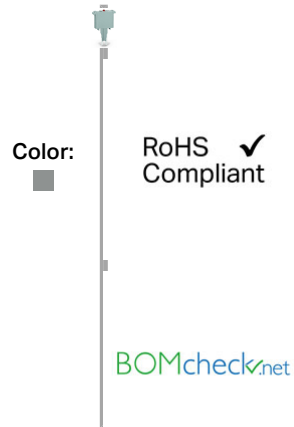

### Item description

#### Safety information 1:

Electrical ratings are given by the fuse and blown fuse indication.

#### Safety information 2:

Leakage current in case of a blown fuse: LED 5 ... 20 mA

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	125 V
Rated current	5 A

#### Geometrical Data

Width	5 mm / 0.197 inch
-------	-------------------

#### Mechanical data

Marking level	without marking level
---------------	-----------------------

#### Material Data






Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0 MJ
Weight	2.79 g

## Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
Country of origin	DE
GTIN	4045454362720
Customs Tariff No.	85366990990

## Compatible products

### clamps

	<b>Item no.: 280-610</b> 3-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-610
	<b>Item no.: 280-616</b> 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-616
	<b>Item no.: 280-686</b> 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-686
	<b>Item no.: 280-816</b> 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-816
	<b>Item no.: 280-916</b> 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®	280-916

Subject to changes.