


# Data sheet | Item number: 282-435

Jumper; insulated; 5-way; Nominal current 30 A



282-435

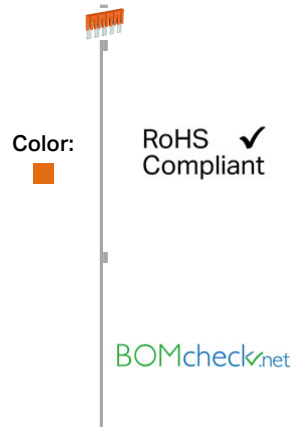

## Data

### Electrical data

#### Ratings per IEC/EN 60664-1

Rated current	30 A
---------------	------

### Material Data


Color	orange
Fire load	0.035 MJ
Weight	5.972 g

### Commercial data

Country of origin	DE
GTIN	4044918607612
Customs Tariff No.	85366990990

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60947	2195540.01
	CCA	EN 60947	NTR NL-



DEKRA Certification B.V.





7522

CSA  
DEKRA Certification B.V.


C22.2 No. 158

1505033

## Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>ABS</b> American Bureau of Shipping	EN 60947	14- HG1293677- PDA
	<b>BV</b> Bureau Veritas S.A.	EN 60947	07436/E0 BV
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	-	TAE00001V2
	<b>LR</b> Lloyds Register	EN 60947	91/20112 (E9)

## UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>UR</b> Underwriters Laboratories Inc.	UL 1059	E45172

## Downloads

## Documentation

## Bid Text

282-435

doc  
24.1 kB

Download



**CAD/CAE - Smart Data**

**CAD data**

3D Download 282-435

URL

Download

---

Subject to changes.

---