


Data sheet | Item number: 286-896


Switching module; with momentary switch; Switching voltage: 250 VAC;

Switching current: 6 A; gray



286-896

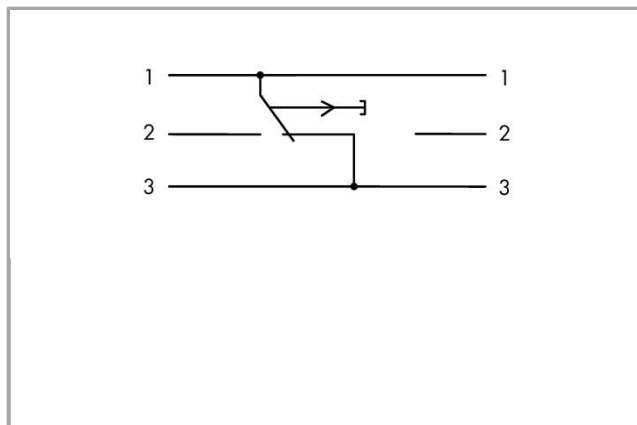

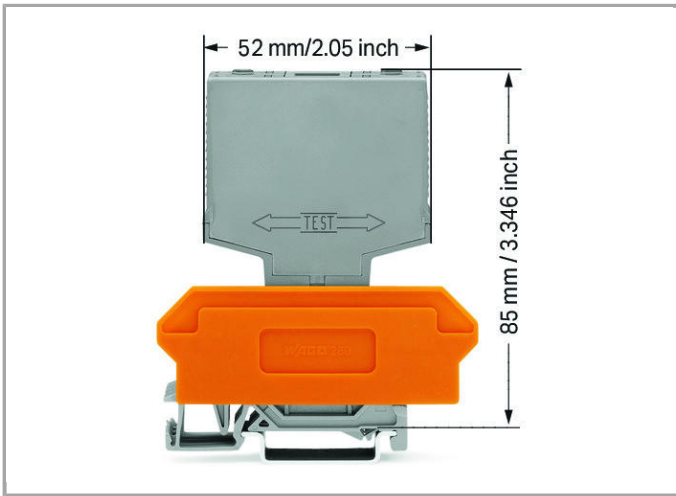

Data

Electrical data

| | |
|---|---|
| Current consumption at supply voltage | 0 |
| Max. switching current (resistive) | 6 A |
| Max. switching voltage | AC 250 V; DC 24 V |
| Contact gap | ≥ 3 mm |
| Electrical life (N.O.; resistive load; 23 °C) | 50 x 10 ³ switching operations |

Geometrical Data

| | |
|---------------------------------------|--------------------|
| Width | 15 mm / 0.591 inch |
| Height from upper-edge of DIN-35 rail | 85 mm / 3.346 inch |
| Depth | 52 mm / 2.047 inch |

Mechanical data

| | |
|------------------|--|
| Type of mounting | Pluggable module for carrier terminal blocks |
| Housing design | Pluggable module for terminal blocks |

Material Data

| | |
|-----------|----------|
| Color | gray |
| Fire load | 0.406 MJ |
| Weight | 19.49 g |

Environmental Requirements




| | |
|---|-----------|
| Surrounding air (operating) temperature at U _N | -20 40 °C |
|---|-----------|

Commercial data









| | |
|--------------------|---------------------------|
| Product Group | 6 (Interface Electronics) |
| Country of origin | DE |
| GTIN | 4045454198190 |
| Customs Tariff No. | 85365080990 |

Compatible products

General accessories

| | | |
|--|--|---------|
|  | Item no.: 280-609 Terminal block for pluggable modules; 12-pole; with 4-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®; 2,50 mm ² ; gray | 280-609 |
|  | Item no.: 280-619 Terminal block for pluggable modules; 6-pole; with 2-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®; 2,50 mm ² ; gray | 280-619 |
|  | Item no.: 280-763 Terminal block for pluggable modules; 12-pole; with 4-conductor terminal blocks; with marker carrier; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®; 2,50 mm ² ; gray | 280-763 |

Marking accessories

| | | |
|--|--|---------------------|
|  | Item no.: 209-701 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 |
|  | Item no.: 209-701/000-002 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-002 |
|  | Item no.: 209-701/000-005 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-005 |
|  | Item no.: 209-701/000-006 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-006 |
|  | Item no.: 209-701/000-007 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-007 |
|  | Item no.: 209-701/000-012 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-012 |
|  | Item no.: 209-701/000-017 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-017 |
|  | Item no.: 209-701/000-023 WSB marking card; as card; not stretchable; plain; snap-on type; white | 209-701 /000-023 |



Item no.: 209-701/000-024

WSB marking card; as card; not stretchable; plain; snap-on type; white

209-701

000-024

Downloads

Documentation

Bid Text

| | | | |
|--|--------------|----------------|----------|
| 286-896 | Jan 15, 2016 | doc 24.6 kB | Download |
| Interface-Bausteine mit Sonderfunktionen | | | |

Additional Information

| | | | |
|--|---------|-----------------|----------|
| Disposal; Electrical and electronic equipment, Packaging | V 1.0.0 | pdf 265.8 kB | Download |
|--|---------|-----------------|----------|

CAD/CAE - Smart Data

CAD data

| | | |
|---------------------|-----|----------|
| 3D Download 286-896 | URL | Download |
|---------------------|-----|----------|

WSCAD

| | |
|----------------|----------|
| WSCAD Universe | Download |
|----------------|----------|

Subject to changes.