


Data sheet | Item number: 400-416/416-298

3-conductor fuse terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 10,00 mm2; light gray



400-416_416-298

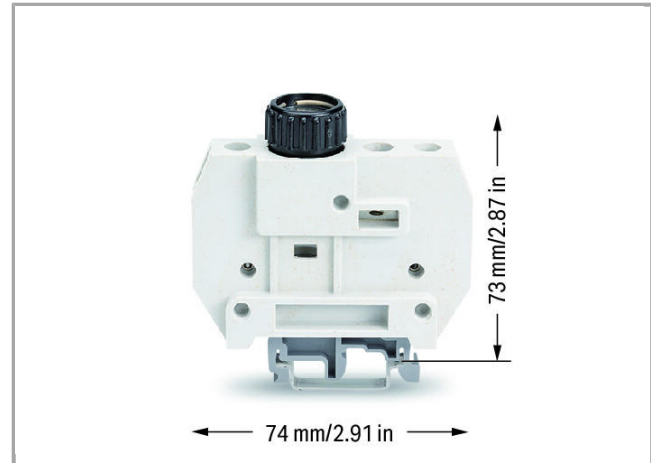

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
Rated impulse voltage (III / 3)	8 kV
Rated current	16 A

Connection data

Connection technology	Screw-clamp connection/Studs
Actuation type	Operating tool
Connectable conductor materials	Copper



Solid conductor	0.2 10 mm ² / 24 8 AWG
Strip length	13 mm / 0.51 inch
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Side-entry wiring
Leiterquerschnitte eindrätig	0.2 mm ²

Geometrical Data

Width	24 mm / 0.945 inch
Height from upper-edge of DIN-35 rail	73 mm / 2.874 inch
Depth	74 mm / 2.913 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail

Material Data

Color	light gray
Weight	99.12 g

Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
Country of origin	FR
GTIN	4017332245920
Customs Tariff No.	85369095990

Downloads

Documentation

Additional Information

Technical explanations	Apr 3, 2019	pdf 2.1 MB	Download
------------------------	-------------	---------------	----------

CAD/CAE - Smart Data

EPLAN

EPLAN Data Portal	Download
-------------------	----------

WSCAD

WSCAD Universe



[Download](#)

Subject to changes.
