


Data sheet | Item number: 400-425/425-216

Screw-type through terminal block; 70 mm²; for DIN-rail 35 x 15 and 35 x 7.5;
70,00 mm²; blue



400-425_425-216

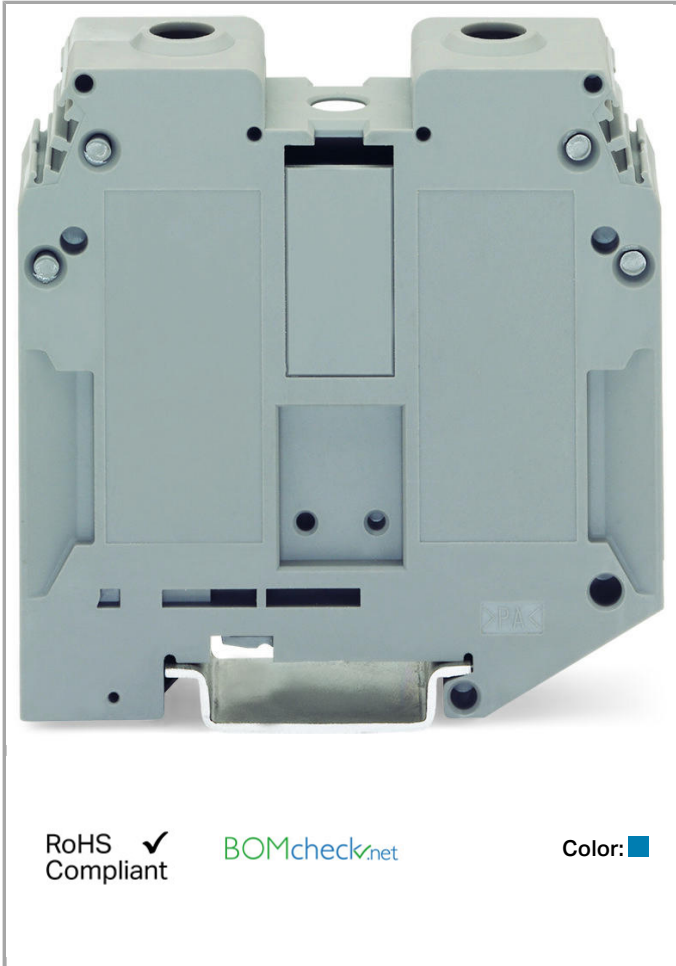

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	1000 V
Rated impulse voltage (III / 3)	8 kV
Rated current	192 A

Connection data

Connection technology	Screw-clamp connection/Studs
Actuation type	Operating tool
Connectable conductor materials	Copper



Solid conductor	16	70 mm ² / 6	2/0 AWG
Strip length	25	27 mm / 0.98	1.06 inch
Total number of connection points	2		
Total number of potentials	1		
Number of levels	1		
Type of wiring	Side-entry wiring		

Geometrical Data

Width	22 mm / 0.866 inch		
Height from upper-edge of DIN-35 rail	67.5 mm / 2.657 inch		
Depth	74 mm / 2.913 inch		

Mechanical data

Design	horizontal		
Type of mounting	DIN-35 rail		
Marking level	Side marking		

Material Data

Color	blue		
Weight	160.9 g		

Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)		
Country of origin	FR		
GTIN	4017332280426		
Customs Tariff No.	85369010000		

Downloads

Documentation

Additional Information

Technical explanations	Apr 3, 2019	pdf 2.1 MB	Download
------------------------	-------------	---------------	----------

CAD/CAE - Smart Data

EPLAN

EPLAN Data Portal	Download
-------------------	----------

WSCAD

WSCAD Universe



[Download](#)

Subject to changes.
