


Data sheet | Item number: 400-425/425-556

Screw-type through terminal block; 95 mm²; for DIN-rail 35 x 15 and 35 x 7.5;
95,00 mm²; blue



400-425_425-556

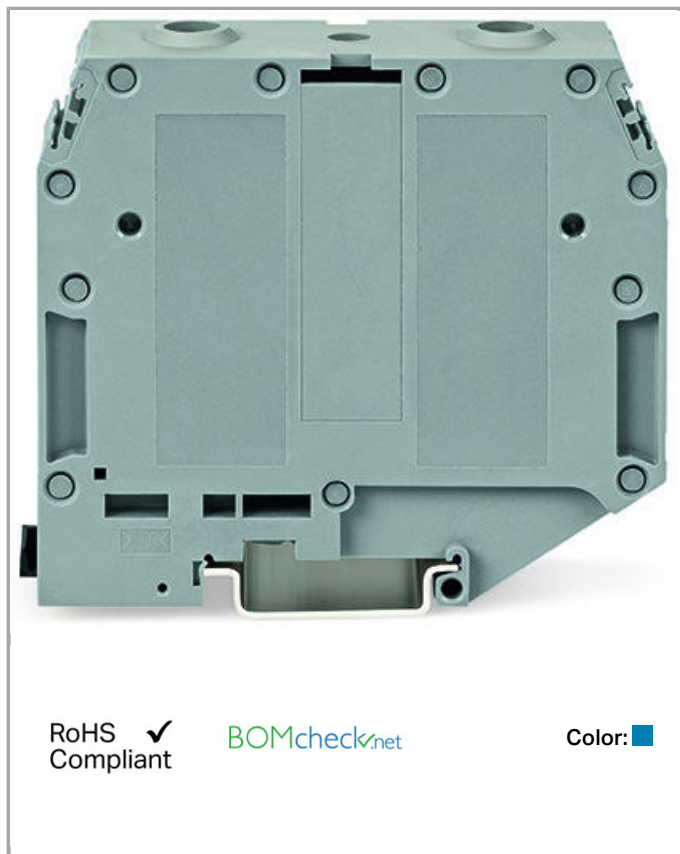

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	1000 V
Rated impulse voltage (III / 3)	8 kV
Rated current	232 A

Connection data

Connection technology	Screw-clamp connection/Studs
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	35 95 mm ² / 2 4/0 AWG
Strip length	25 27 mm / 0.98 1.06 inch
Total number of connection points	2



Total number of potentials	1
Number of levels	1
Type of wiring	Side-entry wiring

Geometrical Data

Width	26 mm / 1.024 inch
Height from upper-edge of DIN-35 rail	72.5 mm / 2.854 inch
Depth	95 mm / 3.74 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Side marking

Material Data

Color	blue
Weight	232.1 g

Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
Country of origin	FR
GTIN	4017332186889
Customs Tariff No.	85369010000

Downloads**Documentation****Additional Information**

Technical explanations	Apr 3, 2019	pdf 2.1 MB	Download
------------------------	-------------	---------------	----------

CAD/CAE - Smart Data**EPLAN**

EPLAN Data Portal	Download
-------------------	----------

WSCAD

WSCAD Universe	Download
----------------	----------



Subject to changes.
