


## Data sheet | Item number: 711-154

Transformer terminal block; 4-pole; CAGE CLAMP® connection for conductors



711-154

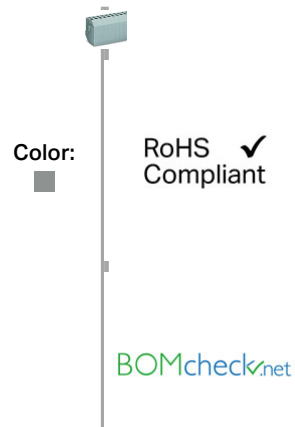

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	800 V
Rated impulse voltage (III / 2)	8 kV
Rated current	25 A

#### Connection data

Connection technology	CAGE CLAMP®
Strip length	9 ... 10 mm / 0.35 ... 0.39 inch
No. of poles	4
Total number of connection points	4
Total number of potentials	4
Number of connection types	1

#### Geometrical Data

Width	30 mm / 1.181 inch
Height	35 mm / 1.378 inch
Depth	23.5 mm / 0.925 inch

#### Material Data

Color	gray
Fire load	0.287 MJ




Weight	14 g
--------	------

### Commercial data


Country of origin	DE
GTIN	4044918819572
Customs Tariff No.	85369010000

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60998	NTR NL-7194
	CCA DEKRA Certification B.V.	EN 60998	2160584.54
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101145

#### UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 1059	E45172

### Downloads

#### CAD/CAE - Smart Data

##### CAD data

3D Download 711-154	URL	Download



Subject to changes.

---