


## Data sheet | Item number: 711-156

Transformer terminal block; 6-pole; CAGE CLAMP® connection for conductors



711-156

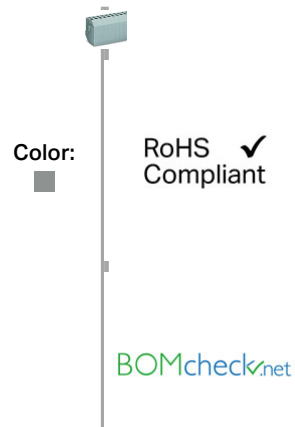

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

|                                 |       |
|---------------------------------|-------|
| Rated voltage (III / 2)         | 800 V |
| Rated impulse voltage (III / 2) | 8 kV  |
| Rated current                   | 25 A  |

#### Connection data

|                                   |                                  |
|-----------------------------------|----------------------------------|
| Connection technology             | CAGE CLAMP®                      |
| Strip length                      | 9 ... 10 mm / 0.35 ... 0.39 inch |
| No. of poles                      | 6                                |
| Total number of connection points | 6                                |
| Total number of potentials        | 6                                |
| Number of connection types        | 1                                |

#### Geometrical Data

|        |                      |
|--------|----------------------|
| Width  | 45 mm / 1.772 inch   |
| Height | 35 mm / 1.378 inch   |
| Depth  | 23.5 mm / 0.925 inch |

#### Material Data

|           |          |
|-----------|----------|
| Color     | gray     |
| Fire load | 0.415 MJ |




|        |         |
|--------|---------|
| Weight | 20.48 g |
|--------|---------|

### Commercial data


|                    |               |
|--------------------|---------------|
| Country of origin  | DE            |
| GTIN               | 4044918819596 |
| Customs Tariff No. | 85369010000   |

### Approvals / Certificates

#### Country specific Approvals

| Logo  | Approval                        | Additional Approval Text | Certificate name |
|---|---------------------------------|--------------------------|------------------|
|   | CCA<br>DEKRA Certification B.V. | EN 60998                 | NTR NL-7194      |
|   | CCA<br>DEKRA Certification B.V. | EN 60998                 | 2160584.54       |
|  | CSA<br>DEKRA Certification B.V. | C22.2 No. 158            | 1101145          |

#### UL-Approvals

| Logo   | Approval                            | Additional Approval Text | Certificate name |
|--|-------------------------------------|--------------------------|------------------|
|  | UL<br>UL International Germany GmbH | UL 1059                  | E45172           |

### Downloads

#### CAD/CAE - Smart Data

##### CAD data

| 3D Download 711-156 | URL | Download |
|---------------------|-----|----------|
|                     |     |          |



Subject to changes.

---