


Data sheet | Item number: 711-180

Transformer terminal block; 10-pole; CAGE CLAMP® connection for conductors



711-180

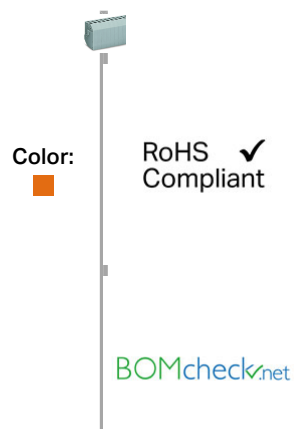

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	800 V
Rated impulse voltage (III / 2)	8 kV
Rated current	25 A

Connection data

Connection technology	CAGE CLAMP®
Strip length	9 ... 10 mm / 0.35 ... 0.39 inch
No. of poles	10
Total number of connection points	10
Total number of potentials	10
Number of connection types	1

Geometrical Data

Width	75 mm / 2.953 inch
Height	35 mm / 1.378 inch
Depth	23.5 mm / 0.925 inch

Material Data

Color	orange
Fire load	0.691 MJ




Weight	33.5g
--------	-------

Commercial data


Country of origin	DE
GTIN	4044918853873
Customs Tariff No.	85369010000

Approvals / Certificates

Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60998	2160584.54
	CCA DEKRA Certification B.V.	EN 60998	NTR NL-7194
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101145

UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 1059	E45172

Downloads

Documentation

Additional Information

pdf
3.6 MB [Download](#)

CAD/CAE - Smart Data

CAD data

3D Download 711-180 [URL](#) [Download](#)



Subject to changes.
