


## Data sheet | Item number: 711-182

Transformer terminal block; 2-pole; CAGE CLAMP® connection for conductors



711-182

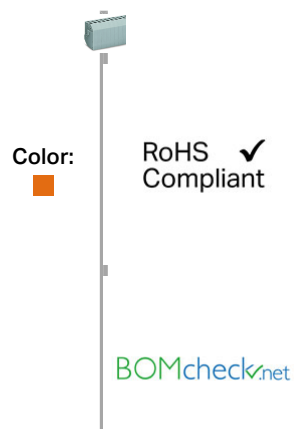

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	800 V
Rated impulse voltage (III / 2)	8 kV
Rated current	25 A

#### Connection data

Connection technology	CAGE CLAMP®
Strip length	9 ... 10 mm / 0.35 ... 0.39 inch
No. of poles	2
Total number of connection points	2
Total number of potentials	2
Number of connection types	1

#### Geometrical Data

Width	15 mm / 0.591 inch
Height	35 mm / 1.378 inch
Depth	23.5 mm / 0.925 inch

#### Material Data

Color	orange
Fire load	0.163 MJ




Weight	7.532 g
--------	---------

### Commercial data


Country of origin	DE
GTIN	4044918965385
Customs Tariff No.	85369010000

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60998	NTR NL-7194
	CCA DEKRA Certification B.V.	EN 60998	2160584.54
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101145

#### UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 1059	E45172

### Downloads

#### CAD/CAE - Smart Data

#### CAD data

3D Download 711-182	URL	Download



Subject to changes.

---