


Data sheet | Item number: 711-408

Transformer fuse terminal block; for fuse 6.35 x 25 mm; CAGE CLAMP® connection for conductors; 22.5 mm wide



711-408

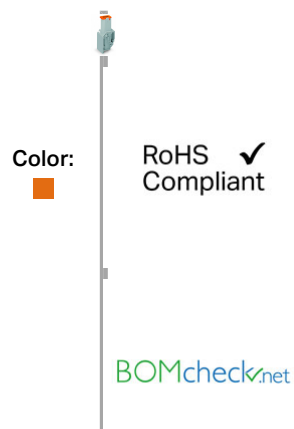

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	800 V
Rated impulse voltage (III / 2)	8 kV
Rated current	10 A

Connection data

Connection technology	CAGE CLAMP®
Strip length	9 ... 10 mm / 0.35 ... 0.39 inch
Total number of connection points	1
Total number of potentials	1
Number of connection types	1

Geometrical Data

Width	22.5 mm / 0.886 inch
Height	57.1 mm / 2.248 inch
Depth	23.5 mm / 0.925 inch


Material Data

Color	orange
Fire load	0.302 MJ
Weight	13.141 g


Commercial data

Country of origin	DE
GTIN	4044918684620
Customs Tariff No.	85369095990

Approvals / Certificates**Country specific Approvals**

Logo	Approval	Additional Approval Text	Certificate name
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101145

UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 1059	E45172

Subject to changes.