


Data sheet | Item number: 726-322

Matrix patchboard; 32-pole; Marking 33-64; Colors of modules: gray/white;
Module marking, side 1 and 2 vertical; for 19" racks



726-322

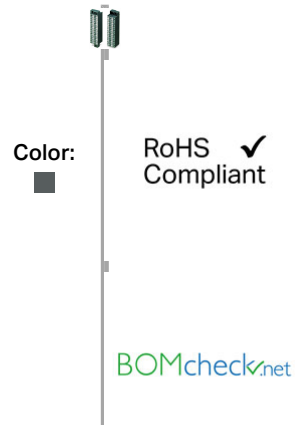

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|-------|
| Rated voltage (III / 3) | 500 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 10 A |

Connection data

| | |
|---|--|
| Connection type (1) | Side 1 |
| Connection technology | CAGE CLAMP® |
| Number of connection points (connection type) | 3 |
| Actuation type | Operating tool |
| Connectable conductor materials | Copper |
| Solid conductor | 0.08 ... 1.5 mm ² / 28 ... 16 AWG |
| Fine-stranded conductor | 0.08 ... 1.5 mm ² / 28 ... 16 AWG |
| Strip length | 8 ... 10 mm / 0.31 ... 0.39 inch |
| Connection type (2) | Side 2 |
| Number of connection points | 3 |
| No. of poles | 32 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|-------|----------------------|
| Width | 34.6 mm / 1.362 inch |
|-------|----------------------|

| | |
|--------|----------------------|
| Height | 132 mm / 5.197 inch |
| Depth | 36.5 mm / 1.437 inch |

Mechanical data

| | |
|---------|---------------|
| Design | slimline |
| Marking | Marking 33-64 |

Material Data




| | |
|-----------|-----------|
| Color | dark gray |
| Fire load | 2.499 MJ |
| Weight | 140.37 g |

Commercial data


| | |
|--------------------|---------------|
| Country of origin | DE |
| GTIN | 4044918456395 |
| Customs Tariff No. | 85369010000 |

Approvals / Certificates

Country specific Approvals

| Logo | Approval | Additional Approval Text | Certificate name |
|--|---------------------------------------|--------------------------|------------------|
|  | CCA DEKRA Certification B.V. | EN 60998 | NTR NL-7623 |
|  | CSA DEKRA Certification B.V. | C22.2 No. 158 | 1101143 |
|  | KEMA/KEUR DEKRA Certification B.V. | EN 60998 | 71-100850 |

UL-Approvals

| Logo | Approval | Additional Approval Text | Certificate name |
|--|-------------------------------------|--------------------------|------------------|
|  | UL UL International Germany GmbH | UL 1059 | E45172 |

Compatible products

tools



Item no.: 210-719
Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm

210-719

check



Item no.: 210-137
Test plug; 2.3 mm Ø; with 500 mm cable

210-137

General accessories



Item no.: 726-902
Adaptor

726-902



Item no.: 726-903
Matrix patchboard

726-903



Item no.: 726-904
Matrix patchboard; insulated

726-904

Jumper



Item no.: 709-107
Wire commoning chain; insulated; 32 connections

709-107

ferrule



Item no.: 216-123
Ferrule; Sleeve for 1 mm² / AWG 18; uninsulated; electro-tin plated

216-123



Item no.: 216-202
Ferrule; Sleeve for 0.75 mm² / 18 AWG; insulated; electro-tin plated

216-202

Marking accessories



Item no.: 209-185
Adaptor

209-185



Item no.: 209-500/209-035
WSB marking card; as card; MARKED; X (100x); not stretchable; Horizontal marking; snap-on type

/ 209-035

209-500



Item no.: 209-501
WSB marking card; as card; not stretchable; plain; snap-on type

209-501



Item no.: 209-501/000-002
WSB marking card; as card; not stretchable; plain; snap-on type

/ 000-002














209-501



Item no.: 209-501/000-005
WSB marking card; as card; not stretchable; plain; snap-on type

/ 000-005

209-501

| | | | |
|--|---|----------|---------|
|  | Item no.: 209-501/000-006 WSB marking card; as card; not stretchable; plain; snap-on type | /000-006 | 209-501 |
|  | Item no.: 209-501/000-007 WSB marking card; as card; not stretchable; plain; snap-on type | /000-007 | 209-501 |
|  | Item no.: 209-501/000-012 WSB marking card; as card; not stretchable; plain; snap-on type | /000-012 | 209-501 |
|  | Item no.: 209-501/000-017 WSB marking card; as card; not stretchable; plain; snap-on type | /000-017 | 209-501 |
|  | Item no.: 209-501/000-023 WSB marking card; as card; not stretchable; plain; snap-on type | /000-023 | 209-501 |
|  | Item no.: 209-501/000-024 WSB marking card; as card; not stretchable; plain; snap-on type | /000-024 | 209-501 |
|  | Item no.: 209-502 WSB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | | 209-502 |
|  | Item no.: 209-566 WSB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | | 209-566 |
|  | Item no.: 210-612 Marking strips; for self-marking; plain; Self-adhesive | | 210-612 |
|  | Item no.: 726-905 Adaptor | | 726-905 |
| Insulation stop | | | |
|  | Item no.: 726-901 Insulation stop; 0.08 - 0.2 mm ² "s" (0.14 mm ² "f-st"); 4 x 3 pieces/strip | | 726-901 |
|  | Item no.: 726-906 Insulation stop; 0.25 mm ² "s"; 0.14 - 0.25 mm ² "f-st"; 4 x 3 pieces/strip | | 726-906 |
|  | Item no.: 726-907 Insulation stop; 0.25 - 0.5 mm ² "s+f-st"; 4 x 3 pieces/strip | | 726-907 |

Downloads

Documentation

Bid Text

| | | |
|---------|----------------|----------|
| 726-322 | doc 25.6 kB | Download |
|---------|----------------|----------|



CAD/CAE - Smart Data

CAD data

3D Download 726-322

URL

Download

Subject to changes.
