
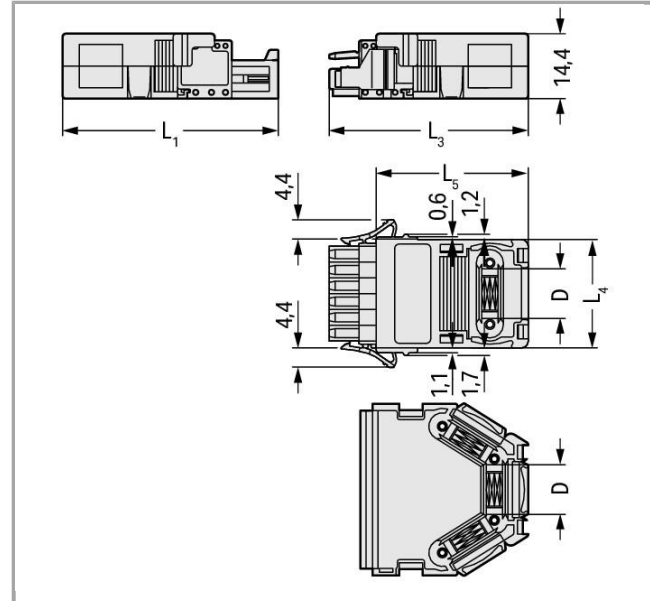


734-602

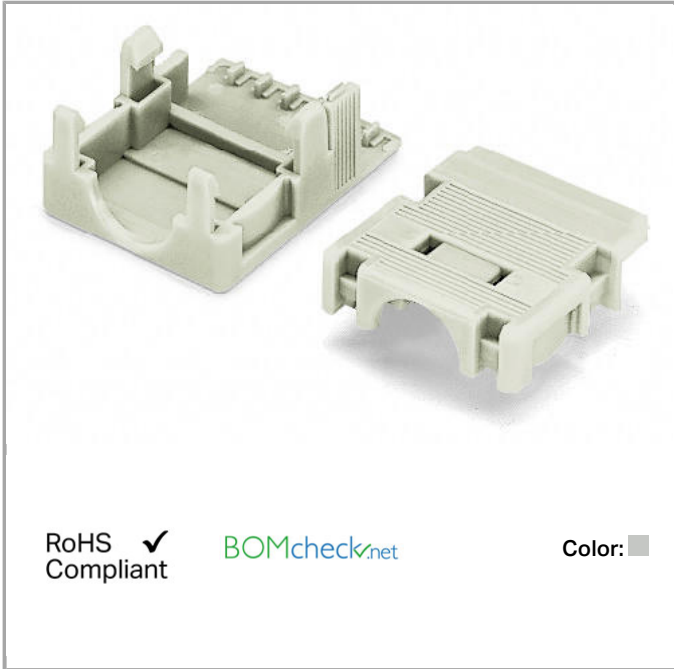

### Item description

- Only for use with cable binders
- Cable binder width: max. 3.6 mm
- 1 x cable outlet, rear

### Data

#### Connection data

No. of poles	2
Number of connection types	1

#### Geometrical Data

Pin spacing	3.5 mm / 0.138 inch
Width	10 mm / 0.394 inch
Height	14.4 mm / 0.567 inch
Depth	32.7 mm / 1.287 inch

#### Material Data

Color	light gray
-------	------------


Fire load	0.056 MJ
Weight	1.84 g

### Commercial data



Product Group	3 (Multi Conn. System)
Country of origin	DE
GTIN	4017332590754
Customs Tariff No.	85389099990

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>CCA</b> DEKRA Certification B.V.	EN 61984	2169534.02
	<b>CCA</b> DEKRA Certification B.V.	EN 61984	nl-54190
	<b>CCA</b> DEKRA Certification B.V.	EN 61984	NL-31142

#### Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>ABS</b> American Bureau of Shipping	-	14- HG1241537- PDA
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	-	TAE000016Z

### Downloads

#### CAD/CAE - Smart Data

##### CAD data

3D Download 734-602	URL	Download
---------------------	-----	----------



Subject to changes.

---