

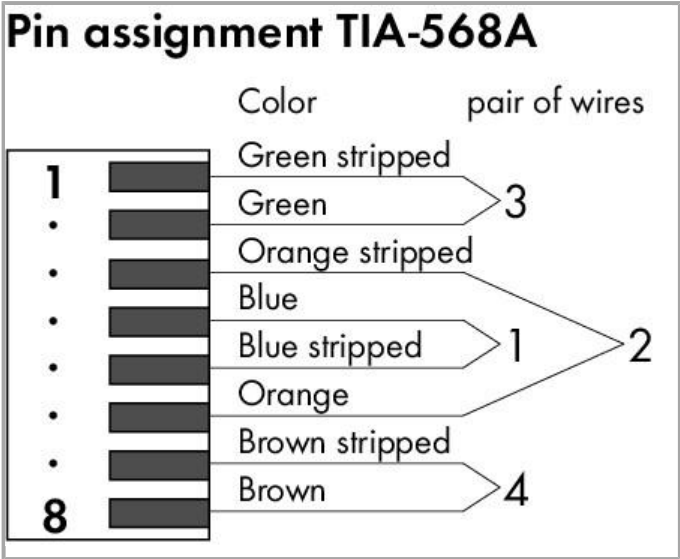


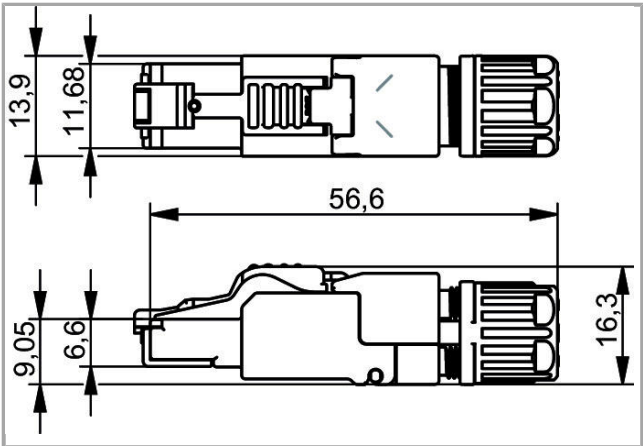

750-978/000-011

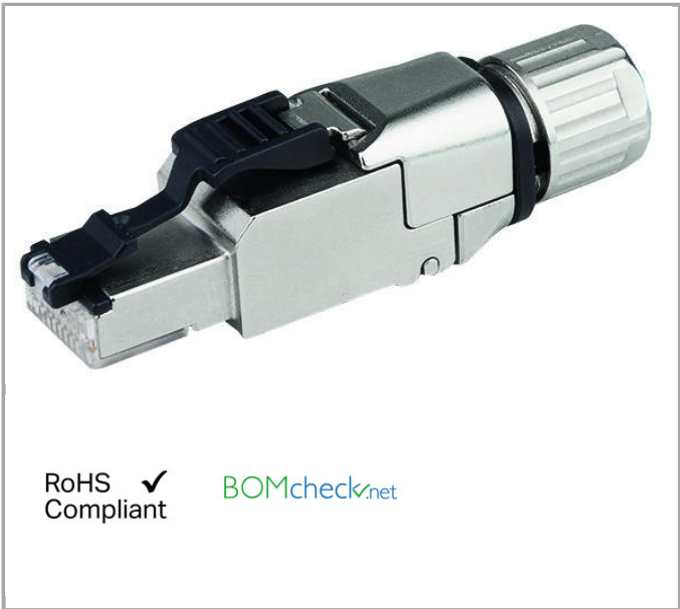

Data

Technical Data

|                                             |               |
|---------------------------------------------|---------------|
| Connection type                             | Stecker RJ-45 |
| No. of poles                                | 8             |
| Leitungsanschlussrichtung zur Steckrichtung | 0°            |
| Communication/Fieldbus                      | Ethernet      |
| Code                                        | TIA-568A      |



|           |   |
|-----------|---|
| Baud rate | - |
|-----------|---|

## Connection data

|                        |                                                   |
|------------------------|---------------------------------------------------|
| Connection type (1)    | IDC-(Schneidklemm-)Kontakt                        |
| Solid conductor        | 0.21 ... 0.32 mm <sup>2</sup> / 24/1 ... 22/1 AWG |
| Stranded conductor (2) | 0.11 ... 0.36 mm <sup>2</sup> / 27/7 ... 22/7 AWG |

## Geometrical Data

|        |         |
|--------|---------|
| Width  | 13.9 mm |
| Height | 16.3 mm |
| Depth  | 56.6 mm |

## Mechanical data

|                                                 |                  |
|-------------------------------------------------|------------------|
| Connection requirement (permissible cable type) | Cat. 6 A         |
| Connectable sheathed cable diameter             | 5.5 ... 10 mm    |
| Housing material                                | Zinc die casting |
| Weight                                          | 22 g             |

## Environmental Requirements

|                                         |                                                                                               |
|-----------------------------------------|-----------------------------------------------------------------------------------------------|
| Surrounding air (operating) temperature | -40 ... 85 °C                                                                                 |
| Surrounding air (storage) temperature   | -40 ... 85 °C                                                                                 |
| Protection class                        | IP20                                                                                          |
| Relative air humidity (no condensation) | 95 %                                                                                          |
| Standards/specifications                | IEC60603-7-51, ISO/IEC 11801, IEEE 802.3an; EIA/TIA 568-C.2; DIN EN 50173-1; UL 1863; UL 2043 |

## Commercial data

|                    |               |
|--------------------|---------------|
| Country of origin  | TW            |
| GTIN               | 4055143586238 |
| Customs Tariff No. | 85366990990   |

## Downloads

### Documentation

#### Bid Text

|                 |                |          |
|-----------------|----------------|----------|
| 750-978/000-011 | doc<br>24.6 kB | Download |
|-----------------|----------------|----------|

#### Additional Information

|                                                          |         |     |          |
|----------------------------------------------------------|---------|-----|----------|
| Disposal; Electrical and electronic equipment, Packaging | V 1.0.0 | pdf | Download |
|----------------------------------------------------------|---------|-----|----------|



Subject to changes.

---