


Data sheet | Item number: 756-5311/090-015

Sensor/Actuator cable; M12A plug; straight; 8-pole; Length: 1.5 m


www.wago.com/756-5311_090-015

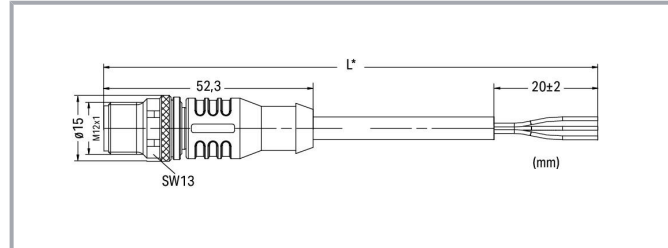

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.

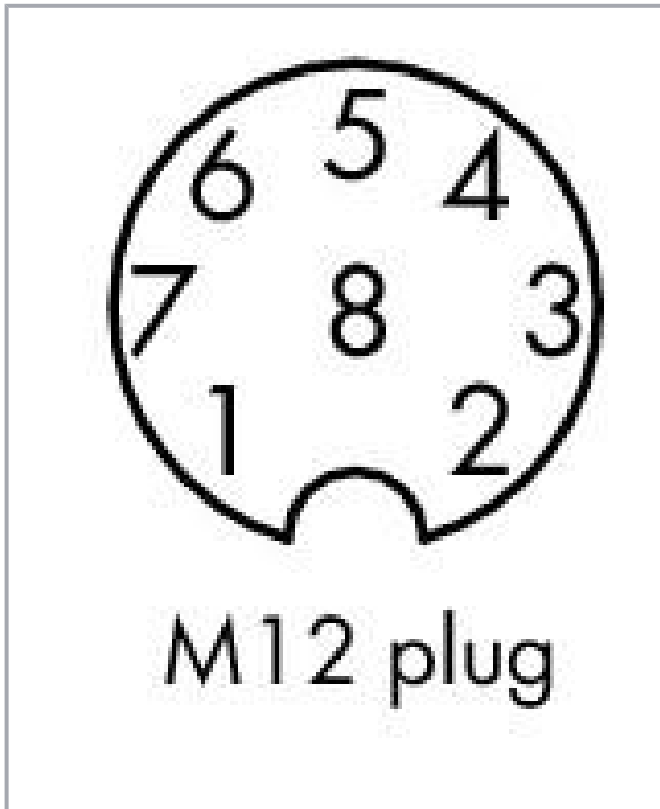

Pin 1 ... 8: 0,25 mm ²	
1	weiß
2	braun
3	grün
4	gelb
5	grau
6	rosa
7	blau
8	rot
----- Schirm	

Item description

Short description:

- PUR, halogen-free
- Suitable for drag chains
- High resistance to microbes, hydrolysis, oil, chemicals and UV radiation
- High chemical resistance
- Cable used: UL listed

Data

Technical data

Connection type	M12 plug - free end
Pole No.	8
Connection point (shielded)	yes
Cable connection direction to mating direction	0°
Connector interface coding (cable/adaptor) 1 1	A-coded

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
 Germantown, WI 53022
 Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
 Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
 We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



Cable length	1.5 m
Operating voltage	250 VAC/DC
Operating current	4 A
Rated surge voltage	1.5 kV

Mechanical data

Bending cycles	2 Mio.
Drag chain suitability	yes
Sheathed cable color	black
Sheathed cable diameter	6.1 ... 6.5 mm
Sheath material	Polyurethane (PUR), halogen-free per DIN VDE 0472 Part 815, flame resistant per IEC 332-2, self-extinguishing
Halogen-free	Yes
Housing material	Polyurethane (PUR)
Contact material	CuSn
Contact plating	CuNi/Au
Tightening torque	1 Nm
Weight	104 g

Environmental requirements

Surrounding air (operating) temperature (dynamic)	-25 ... +90 °C
Surrounding air (operating) temperature (static)	-50 ... +90 °C
Protection type	IP67
Pollution degree (5)	3 per VDE 0110

Commercial data

Packaging type	BOX
Country of origin	HU
GTIN	4050821346388
Customs tariff number	8544429090

Downloads**Documentation****Bid Text**

756-5311/090-015	Sep 20, 2017	doc	Download
doc - Datei		27.6 kB	

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
 Germantown, WI 53022
 Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
 Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
 We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



756-5311/090-015

Feb 19, 2019

xml
3.4 kB

[Download](#)

X81 - Datei

System Description

IP67 Cables and Pluggable Connectors

pdf
293.9 kB

[Download](#)

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 756-5311/090-015

URL

[Download](#)

Sensor/Actuator cable; M12A plug; straight; 8-pole; Length: 1.5 m

Installation Notes

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.